



Brand of NTN corporation

Technical data

UCPLE207

Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, seal with slinger

KIT CONTENT

UC207G2, PLE207

VISUAL (S)

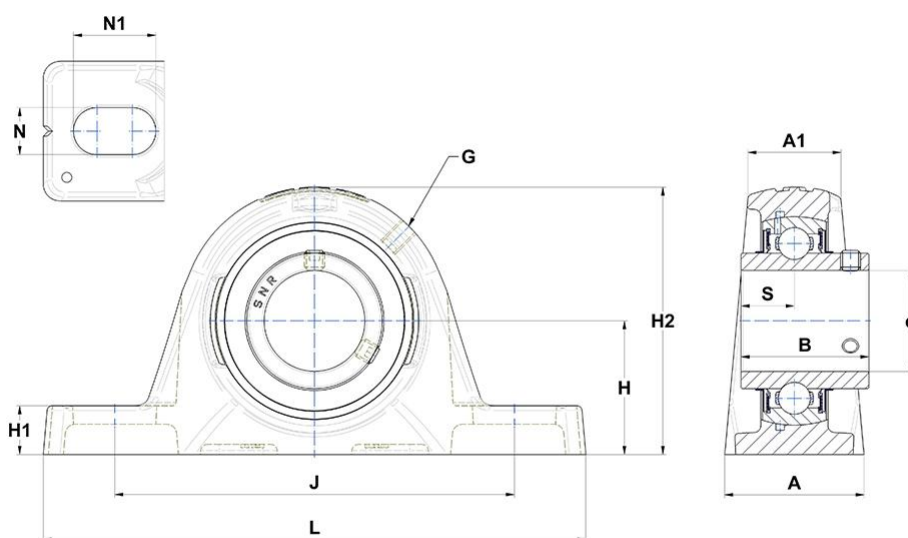

PRODUCT DEFINITION

Brand	SNR
A - Housing width	44,5 mm
A1 - Housing top width	30,5 mm
B - Width of Inner Ring	42,9 mm
d - Shaft diameter	35 mm
G - Grease fitting	M6x1



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

H - Distance mounting base to centerline spheric. seating diam.	46,2 mm
H1 - Housing foot height	16 mm
H2 - Housing height	91,5 mm
J - Mounting holes distance	129 mm
L - Housing length	166 mm
N - Mounting hole dimension	14 mm
N1 - Mounting hole length	21,5 mm
S - Distance front side/bearing centre	17,5 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	25700000 mN
C0 - Static load rating	15200000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	1,57 kg
Recommended tightening torque for set screw	11.5 N-m

