


# Moment compensator FKG-16-B

Part number: 15233

FESTO

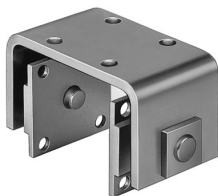

 [General operating condition](#)

## Data sheet

| Feature                                                | Value                                                |
|--------------------------------------------------------|------------------------------------------------------|
| Size                                                   | 16                                                   |
| Radial deviation +/-                                   | 1 mm                                                 |
| Corrosion resistance class CRC                         | 2 - Moderate corrosion stress                        |
| LABS (PWIS) conformity                                 | VDMA24364-B2-L                                       |
| Ambient temperature                                    | -20 °C ... 120 °C                                    |
| Max. permissible long-term load in force direction +/- | 240 N                                                |
| Product weight                                         | 257 g                                                |
| Material driver                                        | Anodised wrought aluminium alloy<br>Galvanised steel |
| Material clevis                                        | Steel<br>Galvanised                                  |
| Material slip piece                                    | Brass                                                |