

DOWNLIGHT LED 35 W 4000 K WT

LEDVANCE DOWNLIGHT LED | LED downlight luminaires



Areas of application

- Direct replacement for 2 x 18 W CFL downlights
- General illumination
- Public areas
- Corridors
- Foyers
- Shops

Product benefits

- Design matches the LEDVANCE DOWNLIGHT luminaire family
- Energy savings up to 60 % (compared to 2 x 18 W CFL luminaires)
- Very homogenous light
- Functional design
- Easy installation with fast connection
- External driver for extended flexibility (compatible with selected DALI drivers)

Product features

- Luminaire efficacy: up to 95 lm/W
- Luminous flux: up to 1,360 lm
- Diameter of required ceiling cut-out: 150 mm
- Available with color temperature: 3,000 K, 4,000 K, 6,500 K
- Wide beam angle: 95°
- Type of protection: IP20
- Lifetime (L70/B50): up to 30,000 h
- Certificates: CE, CB, TUEV SUED



Technical data

Electrical data

Operating mode	Electronic control gear (EVG)
Nominal wattage	35.00 W
Nominal voltage	220...240 V
Mains frequency	50/60 Hz


Photometrical data

Color temperature	4000 K
Luminous flux	3325 lm
Light color (designation)	Cool White
Color rendering index Ra	>80

Light technical data

Beam angle	100.00 °
------------	----------

Dimensions & weight

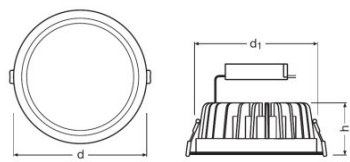

Diameter	220.0 mm
Height	67.0 mm

Colors & materials

Body material	Aluminum
Product color	White
Cover material	Polymethylmethacrylate (PMMA)

Temperatures & operating conditions

Ambient temperature range	-20...45 °C
---------------------------	-------------

Product datasheet

Capabilities

Dimmable	No
----------	----

Certificates & standards

Protection class	II
Type of protection	IP20

Equipment / Accessories

– Recommended DALI driver OTi DALI 15/220...240/1A0 LT2 (4052899324879)

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4058075016347	DOWNLIGHT LED 35 W 4000 K WT	Shipping carton box 8	470 mm x 470 mm x 250 mm	55.23 dm ³	11435.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.