




LED Special E12 T23X51 2W (19W) 180lm 827 Frosted

Article number: 145122

BAI LED Appliance E12 T23X51mm 220-240V 2W (19W) 180lm 2700K IP22 Frosted Refrigerator Sewing machines LED-lamp

LED lamp suitable for household use, including sewing machines, but also extremely suitable in humid situations because of the IP22 value (moisture proof) and shock resistance. Ambient temperature range: -40°C to +40°C.

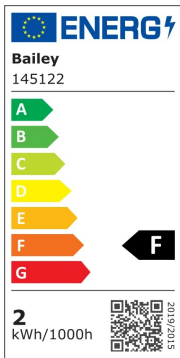

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED Special E12 T23X51 2W (19W) 180lm 827 Frosted
Brand	Bailey
Productseries	LED Special
Producttype	Appliance

ETIM specifications

Socket	E12
Luminous flux [lm]	180 - 180
Nominal voltage [V]	220 - 240
Lamp power [W]	2 - 2
Colour temperature [K]	2700 - 2700
Diameter [mm]	23
Length [mm]	51
Dimmable	No
Lamp shape	Tube, single-ended
Beam angle [°]	300 - 300
Colour	White
Type of glass/cover	Frosted
Lamp designation	Other
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	No
Rated luminous flux according to IEC 62612 [lm]	180
Power factor	0.5
Lamp efficacy [lm/W]	90
Nominal current [mA]	17 - 17
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	White
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP22
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	7500
Weighted energy consumption in 1000 hours [kWh]	2
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG1
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	F
With twilight switch	No
Material of light bulb	Plastic