

## Data Sheet | Item Number: 222-412


CLASSIC Splicing Connector; for all conductor types; max. 4 mm<sup>2</sup>; 2-conductor;  
with levers; gray housing; Surrounding air temperature: max 40°C; 2,50 mm<sup>2</sup>; gray




<https://www.wago.com/222-412>

### Installation Notes


#### Conductor termination

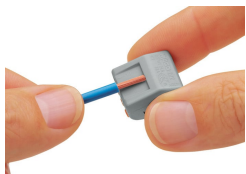

Strip conductor to 9 ... 10 mm (0.35 ... 0.39 inch).

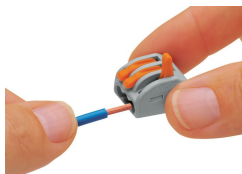

Termination: Lift the lever to open the clamping unit and insert a stripped conductor.

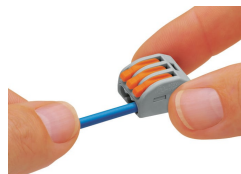


Then, lower the lever to close the clamp.

### Testing



Testing via Profi-LED+ voltage tester (206-806).


### Application

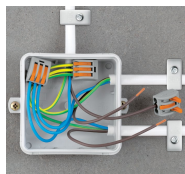

Wiring fine-stranded conductors in junction boxes.



Custom low-voltage lighting system

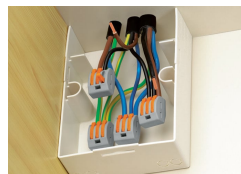

Connecting pre-wired and pre-fabricated components (e.g., in mobile homes).



Lighting fixture connection with fine-stranded wires and power feed

