

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0887328610

Status:


Active

Overview:

USB Products and Solutions

Description:

USB On-The-Go (OTG) Shielded I/O Cable Assembly, USB A-to-Mini B, USB 1.1, 1.0m Length, White

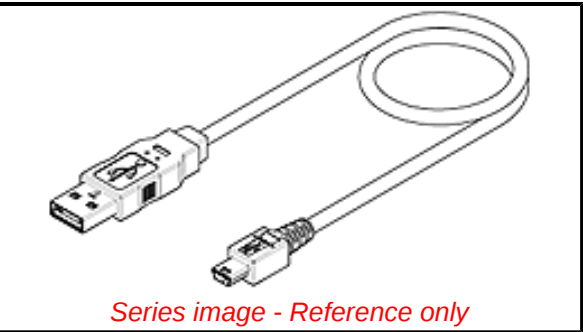

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Packaging Specification PK-88732-005 \(PDF\)](#)

| General                        |                            |
|--------------------------------|----------------------------|
| Product Family                 | Cable Assemblies           |
| Series                         | 68768                      |
| Assembly Configuration         | Dual Ended Connectors      |
| Connector to Connector         | USB Type A-to-Mini-B       |
| Overview                       | USB Products and Solutions |
| Product Name                   | USB                        |
| UPC                            | 756054160060               |
| Physical                       |                            |
| Cable Length                   | 1.0m                       |
| Circuits (Loaded)              | 5                          |
| Color - Resin                  | Black                      |
| Gender                         | Male-Male                  |
| Lock to Mating Part            | Yes                        |
| Material - Plating Mating      | Gold                       |
| Material - Plating Termination | Tin                        |
| Material - Resin               | Polyester                  |
| Net Weight                     | 38.000/g                   |
| Number of Rows                 | 1                          |
| Packaging Type                 | Bag                        |
| Pitch - Mating Interface       | 0.80mm, 2.50mm             |
| Plating min - Mating           | 0.762µm                    |
| Plating min - Termination      | 4.064µm                    |
| Single Ended                   | No                         |
| Termination Interface: Style   | Through Hole               |
| Wire Insulation Diameter       | N/A                        |
| Wire Size AWG                  | 28                         |
| Wire/Cable Type                | Round                      |

| Electrical                    |      |
|-------------------------------|------|
| Current - Maximum per Contact | 1.0A |
| Shielded                      | Yes  |
| Voltage - Maximum             | 30V  |

Material Info

| Reference - Drawing Numbers |                                |
|-----------------------------|--------------------------------|
| Packaging Specification     | PK-88732-005                   |
| Sales Drawing               | SD-887328510, SD-887328510-001 |

| EU ELV                                                        |               |
|---------------------------------------------------------------|---------------|
| Compliant                                                     |               |
| EU RoHS                                                       |               |
| Compliant                                                     |               |
| China RoHS                                                    |               |
| REACH SVHC                                                    |               |
| Not Contained Per - ED/71/2019 (16 July 2019)                 |               |
| Halogen-Free Status                                           |               |
| Not Low-Halogen                                               |               |
| For more information, please visit <a href="#">Contact US</a> |               |
| China ROHS                                                    | Green Image   |
| ELV                                                           | Compliant     |
| RoHS Phthalates                                               | Not Contained |

Search Parts in this Series

68768 Series

Mates With

USB On-The-Go (OTG) Mini-B Receptacle 54819 , 48242 , 500075 , 67503. Universal Serial Bus Shielded Receptacle Type A 67329 , 67226 , 67230 , 89485. 54366 Universal Serial Bus Shielded I/O Receptacle

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION