

Connection plate - ICS25-F22A-7035 - 2203894

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




DIN rail housing, ICS filler, with antenna function cutout, width: 25 mm, height: 7 mm, depth: 22.5 mm, color: light gray (7035)

Your advantages

- ✓ Flexible use, thanks to the modular system and unique modularity in the connection technology
- ✓ Standardized connections such as RJ45, USB, D-SUB and antenna sockets as components that can be integrated
- ✓ Optimal space utilization, as well as adaptability of design, colors, and printing
- ✓ Eight-position DIN rail connectors with parallel and up to two serial contacts for easy module-to-module communication



Key Commercial Data

Packing unit	10 pc
Minimum order quantity	10 pc
GTIN	 4 055626 465999
GTIN	4055626465999
Weight per Piece (excluding packing)	1.630 g
Custom tariff number	85389099
Country of origin	Germany
Sales Key	ACHAEE

Technical data

Item properties

Brief article description	Connection plate
Type	ICS25-F22A-7035
Order No.	2203894
Housing type	DIN rail housing
Housing series	ICS
Range of articles	ICS25
Type	ICS filler, with antenna function cutout

Connection plate - ICS25-F22A-7035 - 2203894

Technical data

Item properties

Max. IP code to attain	IP20
Mounting type	Slot
Ventilation openings present	no

Dimensions

Caption	Schematic representation - for further information, see product drawing in the Download Center
Width [w]	25 mm
Height [h]	7 mm
Depth [d]	22.5 mm

Material data

Housing material	Polyamide
Surface characteristics	untreated
Color (RAL)	light gray (7035)
Flammability rating according to UL 94	V0

Ambient conditions

Ambient temperature (storage/transport)	-40 °C ... 55 °C
Ambient temperature (assembly)	-5 °C ... 100 °C
Ambient temperature (operation)	-40 °C ... 105 °C (depending on power dissipation)
Relative humidity (storage/transport)	80 %

General information

Type of note	Assembly instruction:
Note	Refer to the data sheet for the range in the download area.

Packaging information

Pieces per package	10
Denomination packing units	Pcs.
Outer packaging type	Resealable bag

Standards and regulations

Flammability rating according to UL 94	V0
--	----


Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Connection plate - ICS25-F22A-7035 - 2203894

Dimensional drawing

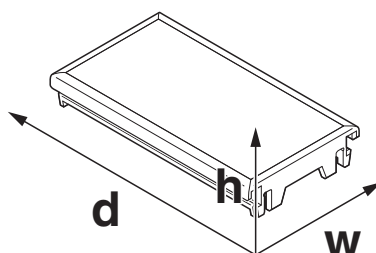

Schematic representation - for further information, see product drawing in the Download Center

Classifications

eCl@ss

eCl@ss 10.0.1	27182702
eCl@ss 11.0	27182702
eCl@ss 5.1	27180506
eCl@ss 6.0	27180800
eCl@ss 7.0	27182702
eCl@ss 9.0	27182702

ETIM

ETIM 6.0	EC001031
ETIM 7.0	EC001031

Approvals

Approvals

Approvals

UL Recognized

Ex Approvals

Approval details

UL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	FILE E 240868
---------------	---	---	---------------