

Home > 1010972003

Part Number: **1010972003**

**General Description**

Series	101
Configuration	SubMin
Description	SUB MINIATURE PANEL INDICATOR
Cap Material And Shape	Stovepipe, plastic
Cap Finish Description	Dark Translucent
Cap Color Desc	Green
Metal Finish Desc	None
Built In Resistor Desc	None
Hardware Desc	Watertight




1010972003



# 004 & 113 SERIES FOR 15/32" MOUNTING HOLE • LIGHT SHIELD


BASE PART NO.	VOLTAGE	FIG
004-1830-29-203	1.35-28	1
004-1930-29-203	1.35-28	2

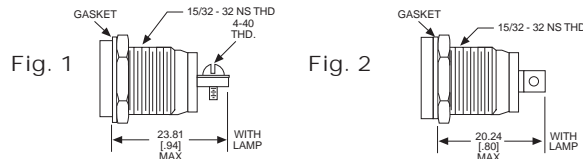

Uses:  
T-1 3/4 MIDGET  
FLANGE BASE  
INCANDESCENT  
LAMP


CAP PART NO.	COLOR	FIG	CAP PART NO.	COLOR	FIG
004-2900-200	NO LENS	3	113-2931-203	RED	4
			113-2937-203	CLEAR	4

Material & Finish: Base - Black Nickel Plated Brass,  
Cap - Black Nickel Plated Brass with High Impact Plastic Lens

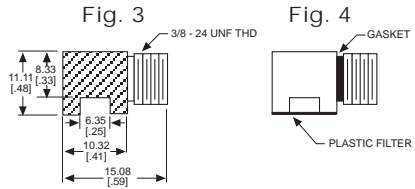

# 101, 111, 140 SERIES FOR 15/32" MOUNTING HOLE • WATERTIGHT

BASE PART NO.	VOLTAGE	FIG
101-3830-09-203	1.35-28	5
101-8430-09-203	1.35-28	6

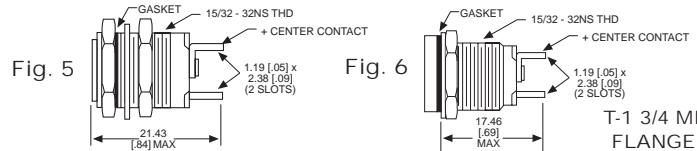

Uses:  
T-1 3/4 MIDGET  
FLANGE BASE  
INCANDESCENT  
LAMP OR BASED  
LED LAMP\*\*

CAP PART NO. *	COLOR	FIG	CAP PART NO. *	COLOR	FIG
101-0937-003	CLEAR	7	111-0113-203	AMBER	8
101-0971-003	RED	7	111-0135-203	WHITE	8
101-0972-003	GREEN	7	111-0137-203	CLEAR	8
101-0973-003	AMBER	7	140-1437-003	CLEAR	9
101-0975-003	WHITE	7	140-1471-003	RED	9
111-0111-203	RED	8	140-1472-003	GREEN	9
111-0112-203	GREEN	8	140-1473-003	AMBER	9
			140-1475-003	WHITE	9

Material & Finish: Base - Black Nickel Plated Brass, Cap - High Impact Plastic;  
Polycarbonate with Black Nickel Bezel (Fig. 8)


\*\* Dialight recommends: Transparent lens caps for Based LEDs; Clear lens caps for Green Based LEDs

**\*PART NUMBER ORDERING CODE**  
**101 - 09xx - 003**  
**140 - 14xx - 003**

Series    Lens Finish:  
 3 = Transparent\*\*  
 7 = Translucent  
 (Not available in clear)


**\*PART NUMBER ORDERING CODE**  
**111 - 01xx - 203**

Series    Lens Finish:  
 1 = Back Frosted  
 (Not available in white)  
 3 = Transparent\*\*

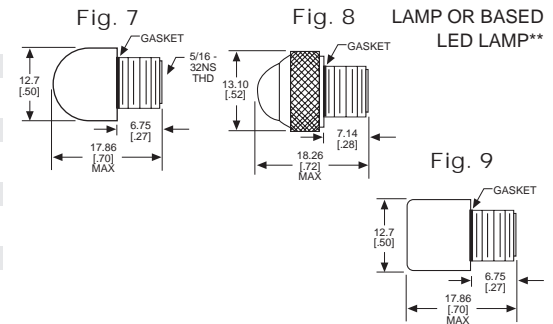


# 812 SERIES FOR 15/32" MOUNTING HOLE • PRESS-TO-TEST

BASE PART NO.	VOLTAGE	FIG
812-1030-09-506	1.35-28	10

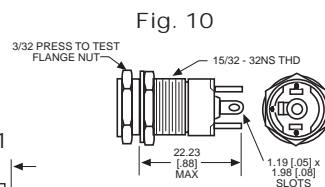

Uses:  
T-1 3/4 MIDGET FLANGE BASE  
INCANDESCENT LAMP OR BASED  
LED LAMP\*\*

CAP PART NO. *	COLOR	FIG
812-0937	CLEAR	11
812-0971	RED	11
812-0972	GREEN	11
812-0973	AMBER	11
812-0975	WHITE	11

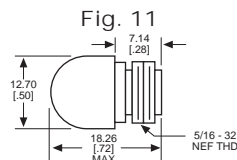

Material & Finish: Base - Black Anodized  
Aluminum, Cap - High Impact Plastic

\*\* Dialight recommends: Transparent lens caps for  
Based LEDs; Clear lens caps for Green Based LEDs

**\*PART NUMBER ORDERING CODE**  
**812 - 09xx**

Series    Lens Finish:  
 3 = Transparent\*\*  
 7 = Translucent  
 (Not available in clear)

Neon and incandescent lamp information on Pages 35 and 36.  
Based LED lamp information on Pages on 37 through 40.

Dimensions in mm [inches]

