


Datasheet

Clear Wedge Filament Indicator Lamp

RS Stock number 106-408



Dimensions: (mm)

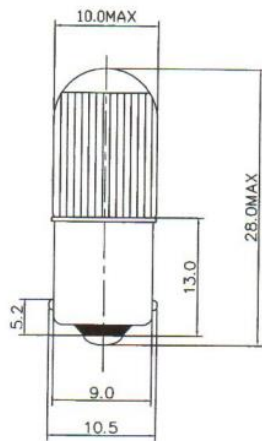

Structure	
Bulb Type	T10x30
Bulb Diameter	Ø10.0Max
Length	28.0Max
Base Type	Wedge Base

Design Characteristics	
Voltage	12V
Amperage	250mA±10%
Gas Type	Neon Filled Gas
Life Hours	50,000Hours