

Reolink Battery Doorbell

Smart 2K 4MP Dual-Band Wi-Fi Battery Doorbell with Expanded Head-to-Toe View



HD

2K 4MP Super HD

Captures every tiny detail in 2K clarity for more peace of mind.



1:1 Head-to-Toe View

Enjoy an expansive 180° diagonal head-to-toe view for full visibility.



Smart Detection

Detects people, vehicles, and packages, alarming you without delay.



Easy Plug and Play

Installation is a breeze - having it up and running in minutes.



5/2.4GHz Wi-Fi 5 Network

Supports dual-band Wi-Fi, meeting diverse connectivity needs.



Local Storage

Offers ample storage with support for up to a 256GB microSD card.



Two-Way Audio

Communicate with visitors or initiate a video call without opening the door.



Smart Home

Seamlessly integrates with other smart home devices for enhanced automation.




Certified Weatherproof

Designed to withstand all weather conditions for steadfast durability.



Day

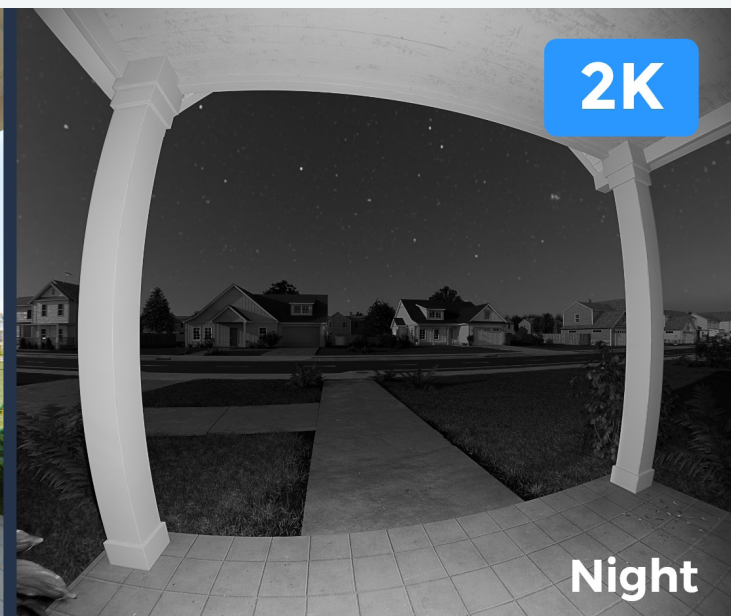

2K

Night

See more, secure more.

Experience 1:1 expansive head-to-toe view in 2K HD, ensuring clarity day and night.



Summon safety, you know who's knocking.

Monitors your surroundings in real-time, keeping you informed and in control.



Simplicity from the first step.

Set up effortlessly, with user-friendly customization options for chime preferences.



Upgraded connectivity with dual-band Wi-Fi.



Enjoy extensive coverage with 2.4GHz band and rapid speeds with 5GHz frequency.



Trusted storage. No monthly fees.

Access crucial video evidence whenever needed, without any recurring fees.

Gallery

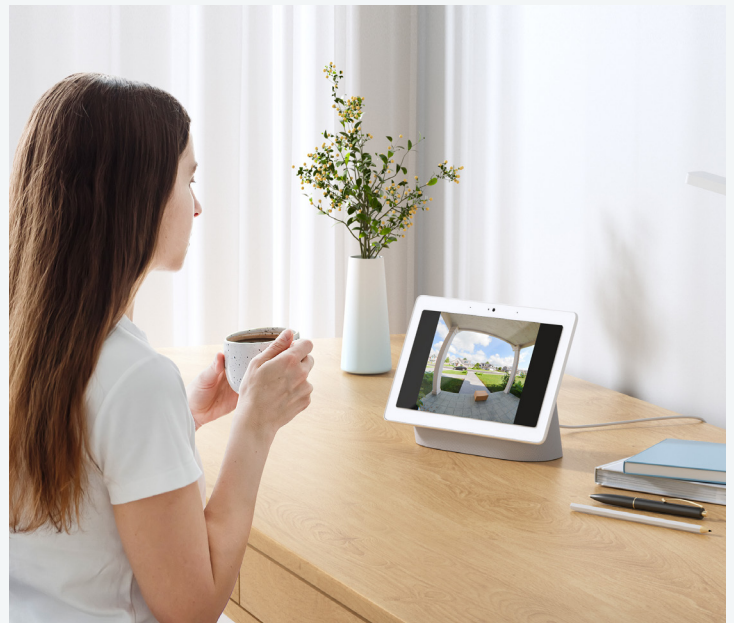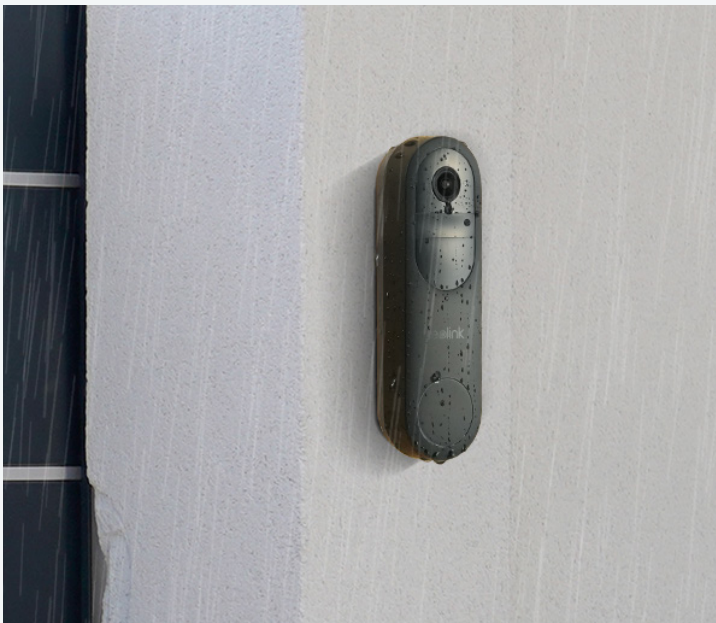

One App/Client for All Control

Stay connected to your home or business anytime, anywhere.




Privacy in Your Hands

We made it a priority to ensure that your privacy is protected and your data is for your eyes only.



Model	Reolink Doorbell Battery	
Video & Audio	Image Sensor	1/3.11" CMOS Sensor
	Video Resolution	Default: 2048X2048 (4 megapixels) @15FPS
	Lens	f=1.2mm F/1.8, fixed
	Video Format	H.265(Clear)/H.264(Other)
	Field of View	Horizontal: 150° Vertical: 150° Diagonal: 180° From Head to Toe
	Pre-Motion Recording	N/A
	Audio	Two-way audio, noise cancellation, echo suppression
	Quick Replies	Support
Power	Hardwired	8-24V AC , 24V DC
	Battery	7000mAh rechargeable battery (Battery life varies based on settings, usage & temperature.)
Interface	Power	Power port
	System	Reset button
	Storage	microSD card slot (Max. 256GB)
	Audio	Built-in 2 microphones & a speaker
WiFi	Wireless Standard	IEEE 802.11 a/b/g/n
	Operating Frequency	2.4GHz/5GHz
	Wireless Security	WPA-PSK/WPA2-PSK
Software	Frame Rate	Mainstream: 10fps - 15fps (default: 15fps) Substream: 10fps - 15fps (default: 15fps)
	Code Rate	Mainstream: 1024Kbps - 4096Kbps (default: 2048Kbps) Substream: 64Kbps - 672Kbps (default: 672Kbps)
	Browsers Supported	Edge, Chrome, Firefox, Safari
	OS Supported	PC: Windows, Mac OS; Smartphone: iOS, Android
	Smart Alarm	Motion detection/person/vehicle/package detection; visitor notification
	Recording Modes	Motion recording (default); 24/7 recording; scheduled recording
	Protocols & Standards	SSL, TCP/IP, UDP, UPNP, SMTP, NTP, P2P
	Work with	Google Assistant, Amazon Alexa
	Rich Notification	Support
Working Environment	Temperature	Operating temperature: -10°C~+55°C (14°F~131°F)
	Humidity	Operating humidity: 10% ~ 90%
	Waterproof	IP65
Size & Weight	Dimension	160.0mm(H)x48.0mm(W)x29.5mm(T)
	Weight	231g
Warranty	Limited Warranty	<u>2-year limited warranty. For support, visit https://support.reolink.com/hc/en-us/.</u>

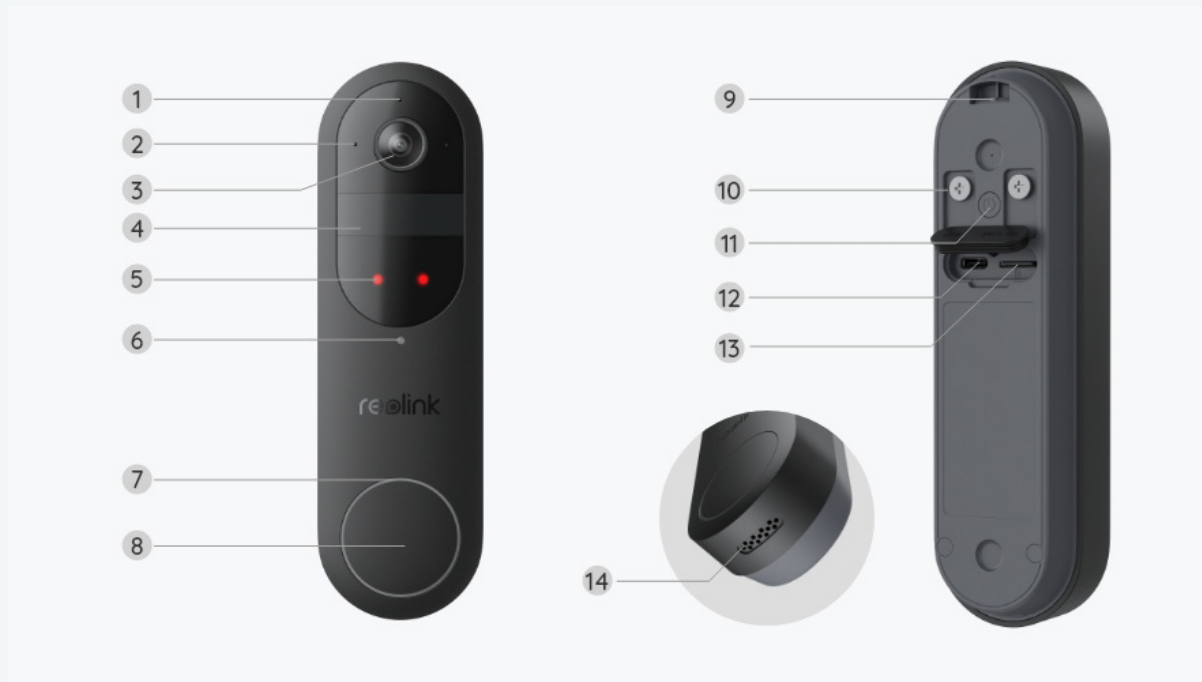

- | | | |
|----------------------|------------------|-------------------------|
| 1 Indicator Light | 2 Microphone | 3 Lens |
| 4 PIR Sensor | 5 Infrared Light | 6 Daylight Sensor |
| 7 Button Ring Light | 8 Button | 9 Lock Mounting Hole |
| 10 Terminal Block | 11 Power Button | 12 Type-C Charging Port |
| 13 microSD Card Slot | 14 Speaker | |

Best Companion



Chime



Horizontal Wedge

Download Free Reolink App & Client

Learn more: <https://reolink.com/software-and-manual/>



Terms and Privacy

Terms and Privacy: Use of the product is subject to your agreement to the Terms of Service and Privacy Policy at reolink.com. Keep out of reach of children.

Limited Warranty

Limited Warranty: This product comes with a 2-year limited warranty. Learn more: <https://reolink.com/warranty-and-return/>