



- fitted with**
- work equipment**
- connected load**
- power consumption**
- luminous flux**
- luminous efficacy**
- light distribution**
- light colour**
- color rendering index (CRI)**
- glare-free**
- system of protection**
- class of protection**
- technology**
- usage**
- luminaire body**
- lamp cover**
- tubular sections**
- balance of articulation joints**
- weight (net)**
- mains lead**
- fastening**
- special features**


- LED
- Energy efficiency category A+
- electronic ballast in housing
- 100-240 V; 50/60 Hz
- approx. 9.5 W
- approx. 600 lm
- approx. 6 lm/W
- direct, narrow-angled beam
- neutral white, approx. 5000 K
- > 80
- screen
- IP 65 (67)
- I
- switchable, continuously dimmable
- push button
- aluminium, anodised, black
- glass screen
- flexible metal tube, black
- friction
- approx. 1.9 kg
- approx. 3,2 m; mains plug
- CEE 7/VII
- screw-down flange, table clamp (accessory), wall bracket (accessory)
- Spot with a 10° angle of radiation



CEE 7/VII

illuminance

distance: 50 cm
Em: 5088 lx
Emax: 30053 lx
Emin: 682 lx

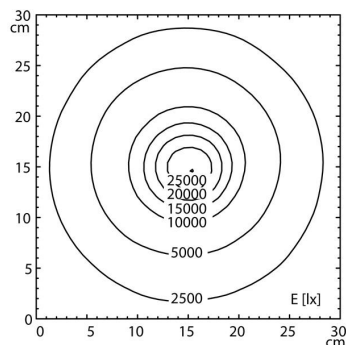

luminous intensity

