


Xenon Flashing Beacons

By D. G. Controls Limited

XFE Series

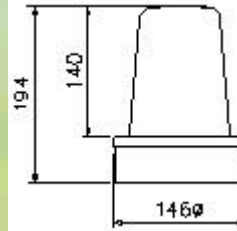

11 Joule model

Supply voltage	12v uc	24v uc	115v ac	230v ac
Supply voltage limits	15%			
Supply current	1.25A	630mA	160mA	80mA
Flash Energy	11J			
Flash/min SH	60 fpm (1Hz)			
Flash/min DH	2 x 60 fpm (2Hz)			
Flash event rate adjustment	User selectable 30, 60 & 90 fepm (0.5, 1 & 1.5Hz)			
Luminous Intensity	220Cd (75,000Cd short duration peak)			
Temperature limits	-40C, +55C			
IEC protection class	IP65			

5 Joule VRA model

Supply voltage	VRA (10 to 100v dc / 10 to 70v ac)
Supply current	630mA @ 12v to 70mA @ 100v
Flash Energy	5J
Flash/min SH	60 fpm (1Hz)
Flash/min DH	n/a
Flash event rate adjustment	n/a
Luminous Intensity	100Cd (35,000Cd short duration peak)
Temperature limits	-40C, +55C
IEC protection class	IP65