


Neodymium shallow pot datasheet

-External thread

- Zinc plated body
- With threaded stem
- 80° max operating temp

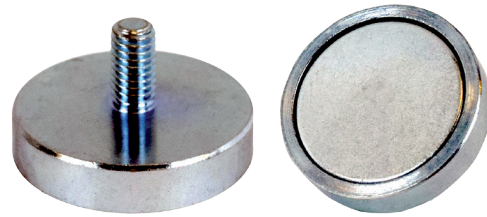

Product Information

Neodymium shallow pot with external thread

Product No.	Eclipse Magnetics Product No.	Diameter <i>mm</i> <i>D</i>	Height <i>mm</i> <i>H</i>	Overall Height <i>mm</i> <i>L</i>	Thread	Weight <i>g</i>	Pull force <i>Newtons</i>
1365478	E1050/NEO/RS	10	4.5	11.5	M3	3.4	25
1365479	E1051/NEO/RS	13	4.5	11.5	M3	3.9	60
1365480	E1052/NEO/RS	16	4.5	13.5	M4	7.1	95
1365481	E1053/NEO/RS	20	6	15.5	M4	14.9	140
1365482	E1054/NEO/RS	25	7	16.5	M5	26.9	200
1365483	E1055/NEO/RS	32	7	18.5	M6	43.9	350
1365484	E1056/NEO/RS	40	8	20	M8	80.1	410

