


Features

- Detachable quick connect cassette for 10X faster wiring
- Designed with circular economy principles
- Screwless faceplate
- Fits 25mm back box, wiring dependent
- 35mm surface mounting box required
- Ideal for tight, or low visibility areas
- Upgradable and repairable USB electronics
- Interchangeable metal faceplates
- Screw terminals with backed out captive screws
- 3 pin safety shutter system

13A 2G DP Switched Socket 20W Dual Outlet USB A & C with Quick Connect Cassette, Matt Black

RS Stock No.: 0778553

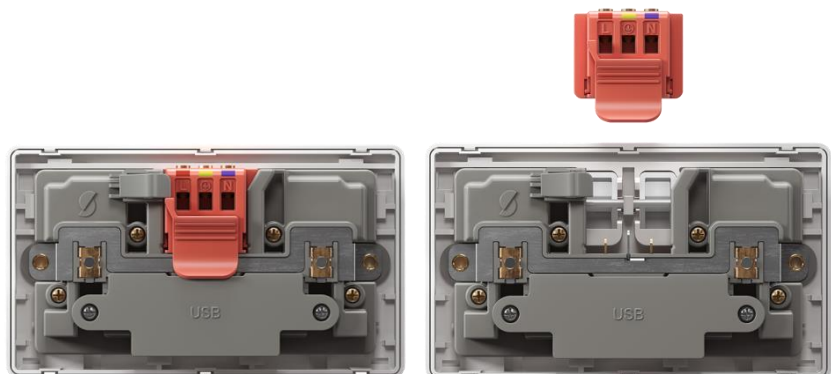

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

This double pole switched socket is designed for fast and reliable installation. It features a patent-pending detachable quick-connect cassette that allows wiring 10 times faster than traditional sockets.

This quick connect system provides secure, consistent connections every time. It helps reduce installation time, and improve on-site efficiency, especially on high-volume or time-sensitive projects, as well as where space is tight, light is limited, and cable length is short.

The sockets are also designed with circular economy principles in mind. The USB electronics can be disassembled for repair or recycling, which helps reduce waste and supports sustainable practices.

Built to meet the needs of electricians, this socket combines robust performance, time-saving installation, and a lower environmental impact.

General Specifications

Finish	Matt black
Faceplate Material	Metal
Pack Quantity	5
Rating	13 Amp 250V AC
Switch Type	Double pole
Terminal Capacity	3 x 2.5mm ² 3 x 4mm ² 2 x 6mm ²
Fixing Centres	120.6mm
IP Rating	IP20
Warranty	25 years (5 years on electronics)

Mechanical Specifications

Mounting Box Depth	25mm (wiring dependent)
Dimensions	H: 86mm W: 146mm D: 32.5mm
Weight	0.276g

Electrical Specifications

Input Voltage Range	220 - 240VAC +/- 10%
Input Frequency Range	50 / 60Hz
Input Current	1A max
Input Current Protection	2A fuse
USB Output Power	20W max
USB Output	5V/3A, 9V/2.2A, 12V/1.67A
Output Dual Output	15W (dynamic balancing)
Charge Protocols	AFC
Over Current Protection	Recover automatically
Over Voltage Protection	Recover automatically
Over-Temperature Protection	Yes
Standby Power	≤0.2W

Classification

UNSPSC (Version)	39121400
------------------	----------

Approvals

Declarations	CE, UKCA, RoHS, Reach, WEEE
Standards	BS 1363-2: 2023 BS EN IEC 62368-1:2020+A11:2020 BS EN IEC 62368-3:2020 EN IEC 61000 6 1:2019 EN IEC 61000-6-3:2021

Similar Products

Stock No.	Brand	Product Name	Attribute 1	Attribute 2	Attribute 3
0778552	RS PRO	2G DP switched socket	Features quick-connect cassette	20W dual outlet USB A & C	Single pack
0778562	RS PRO	2G DP switched socket	Features quick-connect cassette	Double pole switched socket	Single pack
0778563	RS PRO	2G DP switched socket	Features quick-connect cassette	Double pole switched socket	Pack of 5

