




FAG

SES624-324-L [🔗](#)

Plummer block housing




Split plummer block housing for various bearing designs. The SNV series will be replaced by the new SES series in 2022.

Technical information

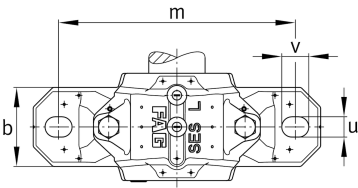

Main Dimensions & Performance Data

D	260 mm	Outside diameter bearing
a	530 mm	Length base
h <sub>1</sub>	321 mm	Height
g	190 mm	Width housing body
K	96 mm	Width bearing seat
≈m	48.4 kg	Weight

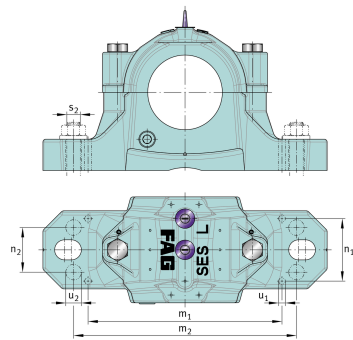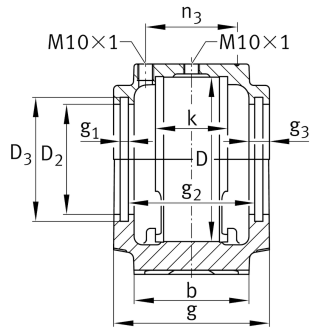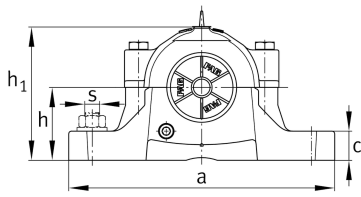

## Dimensions

b	160 mm	Width base
c	60 mm	Height base
h	160 mm	Base to shaft centerline height
m	450 mm	Distance fixing bore
s	31.75 mm	Screw size
s	M30	Size of fixing screws
u	35 mm	Width slot
v	42 mm	Length slot
D 2	157.5 mm	Diameter sealing
D 3	167.5 mm	Diameter sealing groove
D 5	164.7 mm	Outside diameter sealing labyrinth
g 1	6 mm	Width sealing groove
g 2	165.5 mm	Distance sealing
g 3	18 mm	Wall thickness
g 4	43 mm	Distance oil lubrication
m 1	378 mm	Distance holes aligned pins m1
n 3	125 mm	Distance lubrication
n 4	172 mm	Distance lubrication sealing
u 1	12 mm	Bore diameter u1
u 2	26 mm	Bore diameter u2