


# Deep groove ball bearings, single row, shield on one side



Principal dimensions			Basic load ratings		Fatigue load limit $P_u$	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
8	22	7	3,45	1,37	0,057	75000	48000	0,012	608-Z *

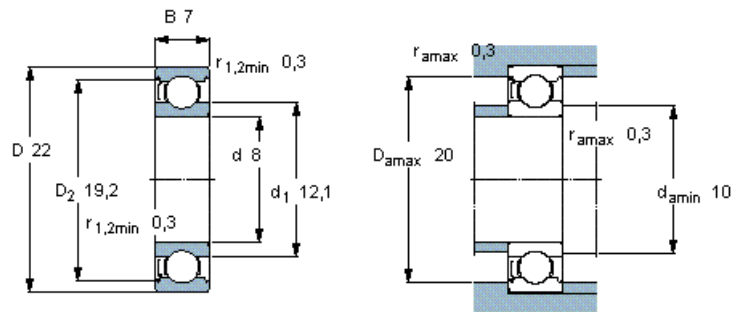

### Calculation factors

$k_r$  0,025  
 $f_0$  12