

5

4

3

2

1

DRAWING NO.  
25-7958

## REVISIONS

01	OFFICIAL RELEASE			
	08-10-09	L	L	T H

2009.09.09  
8:09:41:41  
+0800C  
*Betty*

Description: Colored BNC Boots  
 Part No: 25-7958  
 Application: See table 1  
 Crimp Tool: N/A  
 Impedance: N/A  
 Frequency Range: N/A  
 Material: PVC Color See Table 1  
 RoHS Compliance: Yes  
 Technical Detail: N/A

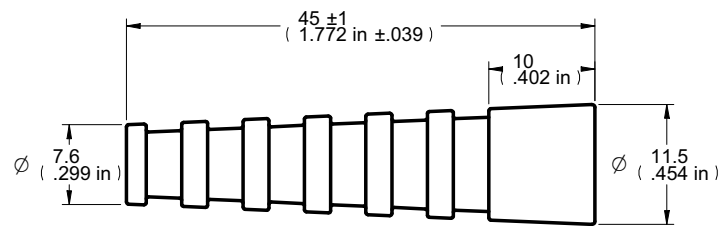


## 受控 CONTROLLED DOCUMENT

编号 P/N	25-7958-CUST	版本 Rev	01	日期 Rel'd Date	SEP 14, 09
-----------	--------------	-----------	----	------------------	------------

TABLE 1

PART NO.	CABLE TYPE	COLOR
25-7958BK	RG-58,141	BLACK
25-7958RE	RG-58,141	RED
25-7958BU	RG-58,141	BLUE
25-7958YE	RG-58,141	YELLOW
25-7958GN	RG-58,141	GREEN

DIM OUTLINE

CUSTOMER COPY

TOLERANCE UNLESS OTHERWISE SPECIFIED		DRAWN BY LINDA.WU	DATE 08-10-09
DECIMALS	mm	CHECKED BY LINDA.WU	DATE 08-10-09
X	± 0.5	APPROVED BY THOMAS	DATE 08-10-09
X.X	± 0.3	U/M	mm
X.XX	± 0.1		
ANGLES	± 0.5°		

TITLE  
COLORED BNC BOOTSTHIS DRAWING WAS PRODUCED BY COMPUTER,  
DO NOT SCALE DRAWING OR UPDATE MANUALLY.SHEET  
1 OF 1DRAWING NO.  
25-7958SIZE  
A

5

4

3

2

1