




Connectors > Connector Accessories > Connector Hardware

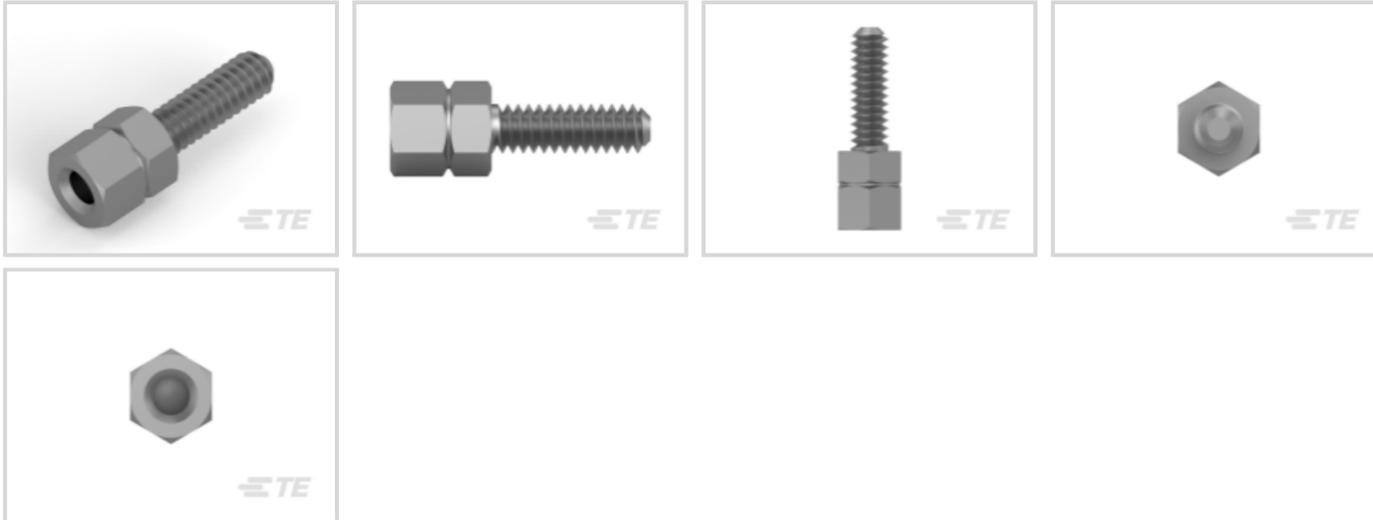

Hardware Accessory Function: **Latching, Locking & Retention**

Connector Hardware Accessory Type: **Female Screwlock**

Features

Product Type Features

Hardware Accessory Function	Latching, Locking & Retention
Connector Hardware Accessory Type	Female Screwlock

Mechanical Attachment

Thread Size	4-40 UNC
-------------	----------

Dimensions

Thread Length	9.7 mm[.382 in]
Product Feature Length	15.9 mm[.62 in]

Packaging Features

Packaging Method	Box
Packaging Quantity	1000

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	有害物质含量超出标准 Restricted Substance(s) Above Threshold

EU REACH Regulation (EC) No. 1907/2006

Current ECHA Candidate List: JUNE 2025
(250)

Candidate List Declared Against: JUNE
2025 (250)

SVHC > Threshold:

Pb (3.5% in 3441353)

Article Safe Usage Statements:

Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.

Halogen Content

Low Halogen - Br, Cl, F < 900 ppm per
homogenous material. Also BFR/CFR/PVC
Free

Solder Process Capability

Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Also in the Series | AMPLIMITE Kit



Connector Caps & Covers(2)



Connector Hardware(94)



Connector Seals & Cavity Plugs(4)




Connector Strain Relief(131)


Customers Also Bought



TE Part #5053122016
RNF-100-1/4-6-STK

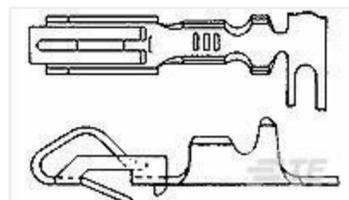

TE Part #3-61668-1
BIF-LEAF CONT CR/SNAP SN/BR

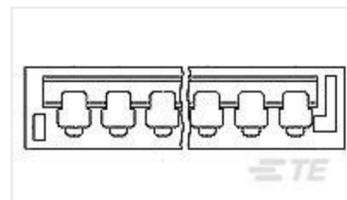

TE Part #640136-2
02P EDGE CONN HSG, BIF-LEAF



TE Part #826632-6
6P AMPMODU II PIN HDR



Documents

Product Drawings

HD-20SCHRAUB-SICHRG

English

CAD Files

3D PDF

3D

Customer View Model

[ENG_CVM_CVM_1-828102-1_J.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1-828102-1_J.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1-828102-1_J.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.