

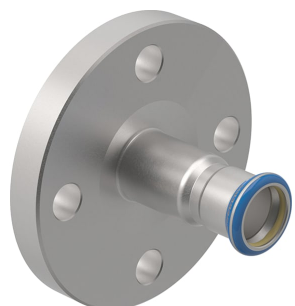


Geberit Mapress Stainless Steel flange PN 10/16, with pressing socket (gas)

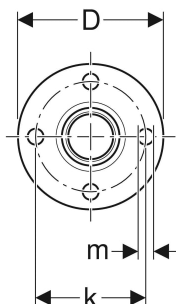

Example image

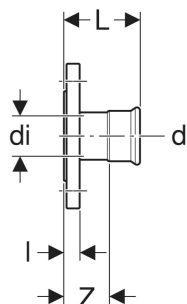

APPLICATION PURPOSES

- For natural gases
- For liquefied gases
- For biogases
- For natural and liquefied gases

CHARACTERISTICS

- Pressing indicator

- Leaky if unpressed
- Marked in yellow
- Seal ring made of HNBR, yellow
- Silicone-free (LABS-free)
- Pressing socket with yellow protection plug
- Design B1 (raised sealing strip with standard sealing strip), EN 1092-1

TECHNICAL DATA

Product material CrNiMo steel 1.4401 (EN 10088)

ACCESSORIES

- Geberit bolt set for flange connection, made of CrNi steel
- Geberit flange gasket, fibre composite material PN 10/16

Art. no.	DN	d _ø mm	di _ø mm	D cm	k mm	m mm	L cm	l cm	Z cm	n pc	PN bar
34204	25 / 20	22	19	11.5	85	14	6.1	1.8	4	4	10 / 16
34205	25	28	25	11.5	85	14	6.9	1.8	4.6	4	10 / 16
34206	32	35	32	14	100	18	7.2	1.8	4.6	4	10 / 16
34207	40	42	39	15	110	18	7.9	1.8	4.9	4	10 / 16

<i>Art. no.</i>	<i>DN</i>	<i>d_ø</i> <i>mm</i>	<i>d_{f, ø}</i> <i>mm</i>	<i>D</i> <i>cm</i>	<i>k</i> <i>mm</i>	<i>m</i> <i>mm</i>	<i>L</i> <i>cm</i>	<i>l</i> <i>cm</i>	<i>z</i> <i>cm</i>	<i>n</i> <i>pc.</i>	<i>PN</i> <i>bar</i>
34208	50	54	51	16.5	125	18	8.7	1.8	5.2	4	10 / 16
34209	65	76.1	72	18.5	145	18	11.8	1.8	6.5	4	10 / 16
34210	80	88.9	84.8	20	160	18	12.5	2	6.5	8	10 / 16
34211	100	108	103.9	22	180	18	13	2	5.5	8	10 / 16