


ARR Indust X7R HT200C, Ceramic, 1 uF, 10%, 50 VDC, X7R, Commercial, High Temperature, Lead Spacing = 5.08mm

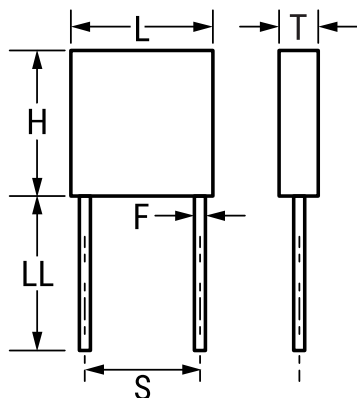

Dimensions

L	7.62mm MAX
H	7.62mm MAX
T	2.54mm MAX
S	5.08mm +/-0.38mm
LL	31.75mm MIN
F	0.51mm +/-0.05mm

Packaging Specifications

Packaging:	Bulk, Bag
Packaging Quantity:	1

General Information

Supplier:	KEMET
Series:	ARR Indust X7R HT200C
Style:	Radial
Description:	Commercial, High Temperature
Features:	Commercial
RoHS:	No
Prop 65:	⚠ WARNING: Cancer and reproductive harm - www.p65warnings.ca.gov .
REACH:	SVHC (Pb – CAS 7439-92-1)
Termination:	Gold
Failure Rate:	N/A
Testing and Reliability:	Standard

Specifications

Capacitance:	1 uF
Capacitance Tolerance:	10%
Voltage DC:	50 VDC
Dielectric Withstanding Voltage:	125 VDC
Temperature Range:	-55/+200C
Temperature Coefficient:	X7R
Dissipation Factor:	2.5%
Insulation Resistance:	1 GOhms