


290

Plug, beaded

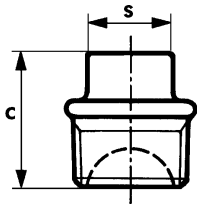


ISO T9

* solid

Dimension	Code	c	s
• S 1/8 □ *	770 290 101	20	7
• V 1/8 □ *	770 290 201		
• S 1/4 □ *	770 290 102	24	8
• V 1/4 □ *	770 290 202		
• S 3/8	770 290 103	28	10
• V 3/8	770 290 203		
• S 1/2	770 290 104	32	11
• V 1/2	770 290 204		
• S 3/4	770 290 105	37	17
• V 3/4	770 290 205		
• S 1	770 290 106	41	19
• V 1	770 290 206		
• S 1 1/4	770 290 107	43	22
• V 1 1/4	770 290 207		
• S 1 1/2	770 290 108	44	22
• V 1 1/2	770 290 208		
• S 2	770 290 109	53	27
• V 2	770 290 209		
• S 2 1/2	770 290 110	55	32
• V 2 1/2	770 290 210		
• S 3	770 290 111	62	36
• V 3	770 290 211		
• S 4	770 290 112	73	41
• V 4	770 290 212		

291

Plug, plain, hollow

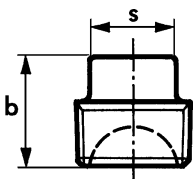

ISO T8

* solid

Dimension	Code	b	s
• S 1/8 □ *	770 291 101	16	7
• V 1/8 □ *	770 291 201		
• S 1/4 □ *	770 291 102	18	8
• V 1/4 □ *	770 291 202		
• S 3/8 □ *	770 291 103	20	10
• V 3/8 □ *	770 291 203		
• S 1/2	770 291 104	24	11
• V 1/2	770 291 204		
• S 3/4	770 291 105	28	17
• V 3/4	770 291 205		
• S 1	770 291 106	33	19
• V 1	770 291 206		
• S 1 1/4	770 291 107	36	22
• V 1 1/4	770 291 207		
• S 1 1/2	770 291 108	37	22
• V 1 1/2	770 291 208		
• S 2	770 291 109	44	27
• V 2	770 291 209		
• S 2 1/2	770 291 110	52	32
• V 2 1/2	770 291 210		
• S 3	770 291 111	59	36
• V 3	770 291 211		
• S 4	770 291 112	66	41
• V 4	770 291 212		