


SIVACON, Roof, with Ventilation openings with Ventilation openings IP20, W: 1200 mm, T: 600 mm, zinc-plated

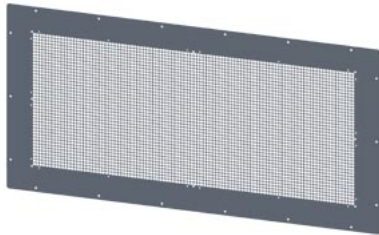

Model			
product brand name		SIVACON	
product designation		top plate	
design of the product		With ventilation openings	
design of the surface		zinc plated	
design of the product EMC version		No	
Protection class			
protection class IP		IP20	
Suitability			
suitability for use for outside use		No	
Product details			
product component			
• cable entry		No	
• ventilation		Yes	
Mechanical Design			
width		1 200 mm	
depth		600 mm	
ventilation cross section outlet can be used		2 742 cm²	
net weight		8.6 kg	
material		steel	
Approvals Certificates			
General Product Approval		Test Certificates	other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other

Environment

[Miscellaneous](#)

Siemens
EcoTech



[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1026-2UD20-0A>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1026-2UD20-0A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1026-2UD20-0A

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

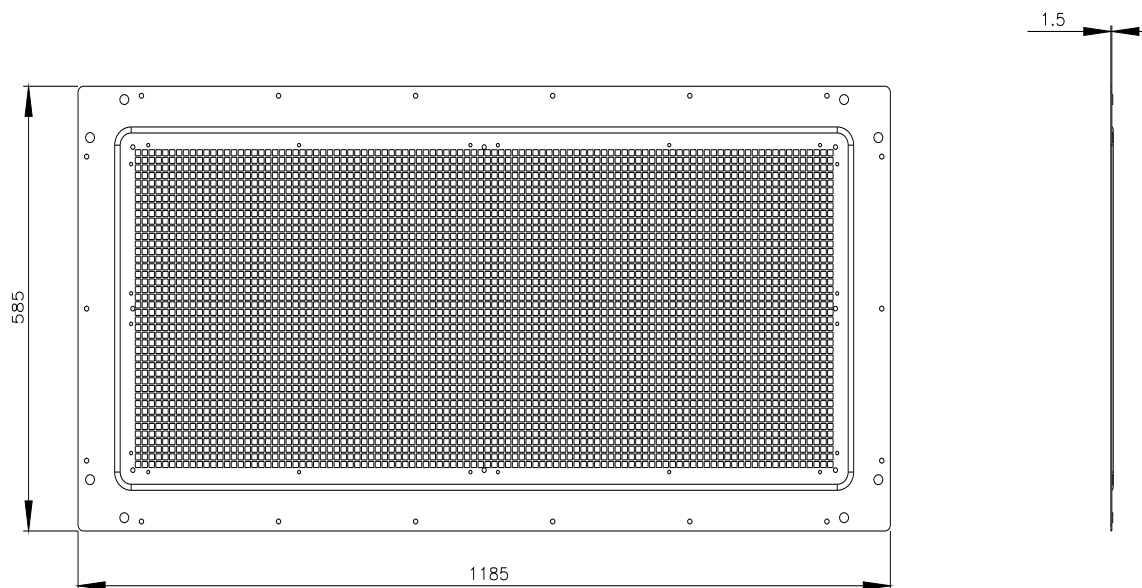

last modified:

1/16/2025 

