



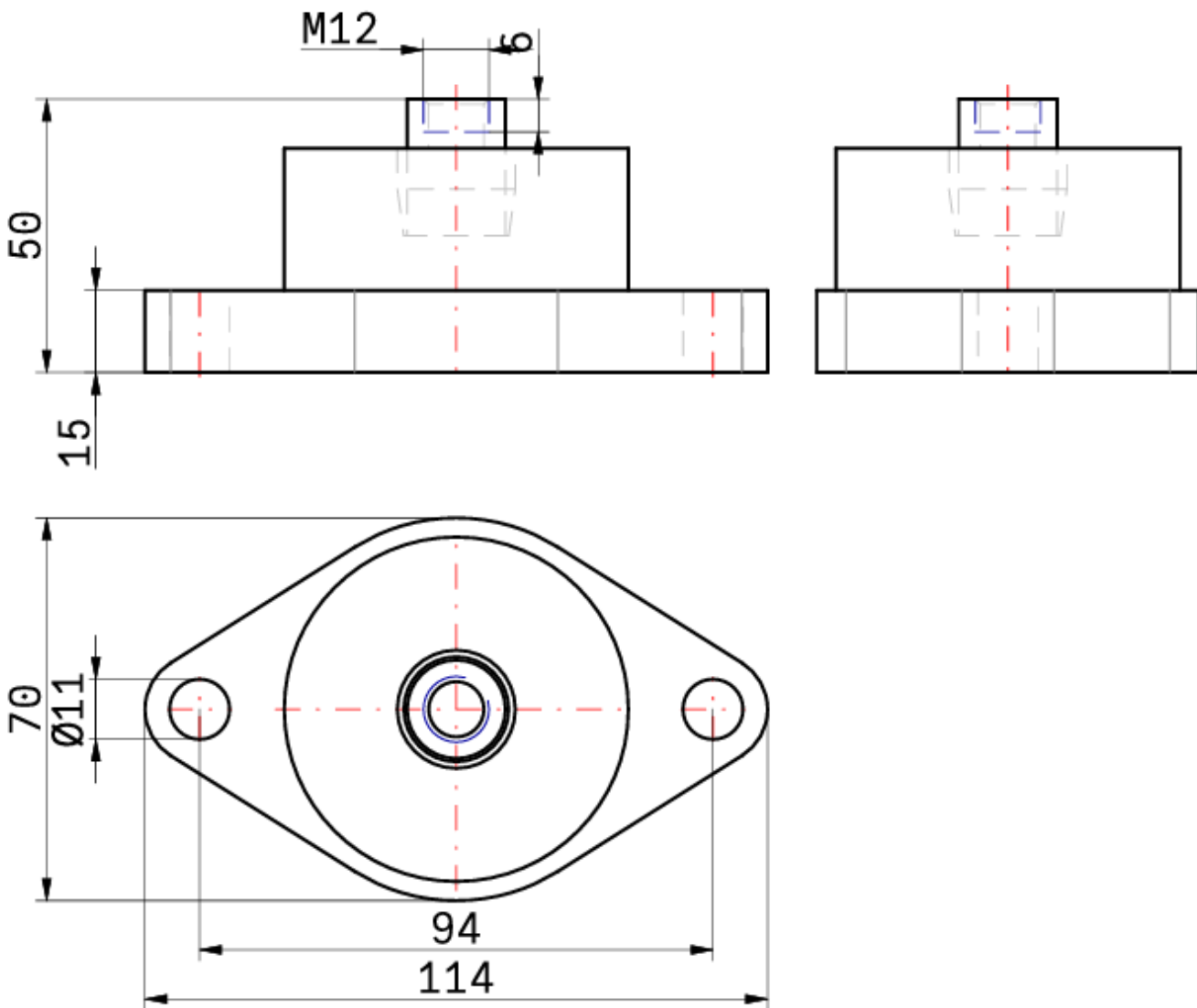

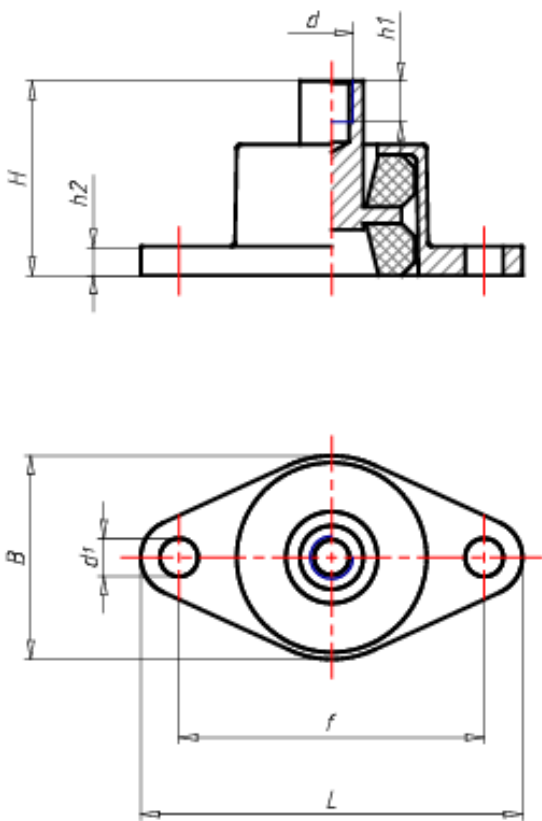

Code	629688
B	70
L	114
H	50
d	M12
d1	11
h1	6
h2	15
f	94
Min load [N]	750
Max load [N]	3900
Min deflection [mm]	1
Max. deflection [mm]	3
Shore A	60
Weight (in g)	340