



SK 174 B 02


E 232 E-8/230



SK 176 B 02


E 232-HLM

Maße in mm

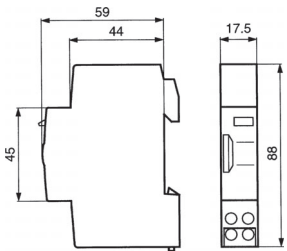

E 232-230

SK 0075 Z 02

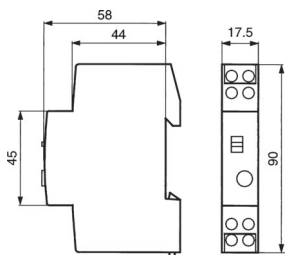


**E 232 E
E 232 HLM**

SK 0093 Z 02

Auswahltablelle


Verlustleistung		Bestellangaben		bn	Preis	Preis-	Gewicht	Verp.
W	Zeitbereich	Kurzbezeichnung	Erzeugnis-Nr.	40 16779	1 Stück	gruppe	1 St.	ein-
				EAN	€		kg	Stück
1 VA	1 ... 7 min.	E 232-230	GH E232 1001 R0011	54824 3			0,081	10
4,5 VA	1 ... 12 min.	E 232 E-230	GH E232 1001 R0012	54825 0			0,083	10
4,5 VA	1 ... 12 min.	E 232 E-8/230	GH E232 1001 R0013	54826 7			0,092	10
4,5 VA	1 ... 12 min.	E 232 E-8/230 Plus	GH E232 1001 R0014	54827 4			0,093	10
6 VA	20 ... 60 sec.	E 232-HLM	GH E232 1001 R0010	54828 1			0,075	10

Schaltbilder

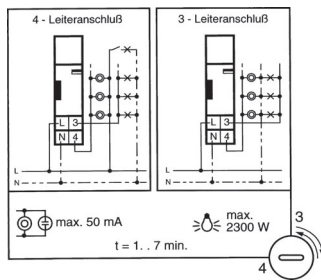


E 232-230

SK 0076 Z 02

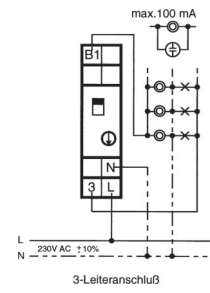


E 232 E-230

SK 0249 Z 02

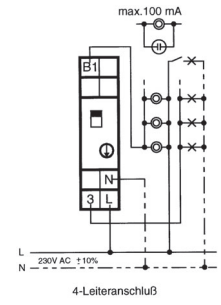


E 232 E-230

SK 0084 Z 02

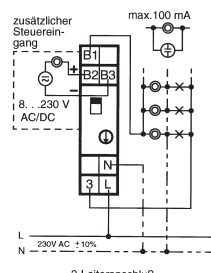


E 232 E-8/230

SK 0248 Z 02

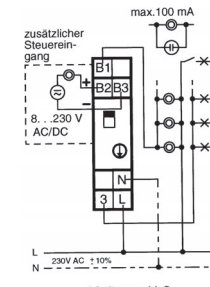


E 232 E-8/230

SK 0082 Z 02

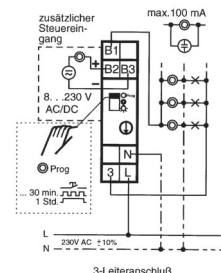


E 232 E-8/230 Plus

SK 0086 Z 02

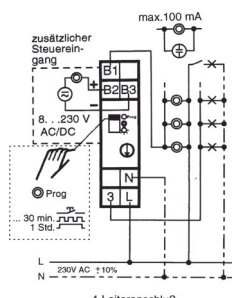


E 232 E-8/230 Plus

SK 0087 Z 02

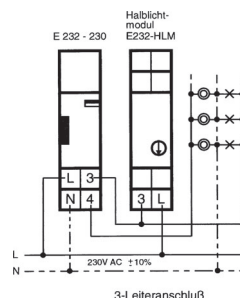


E 232 HLM

SK 0088 Z 02

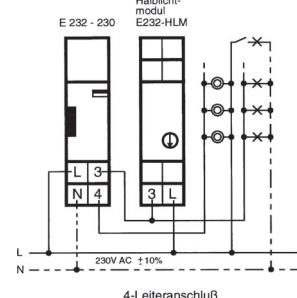


E 232 HLM

SK 0090 Z 02

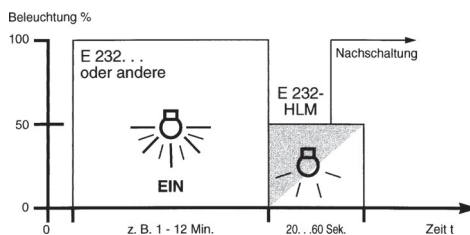

Zeitablauf Treppenlicht-Zeitschalter mit Halblichtmodul E 232-HLM

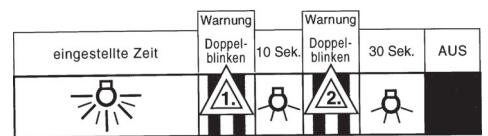

Warnfunktion beim E 232 E-8/230 Plus

SK 0105 Z 02