


KEMET Part Number: SHBC24N-2R0A0219V
(UALS4N2R0A0219)

KEMET, SHBC, AC Line Filters, Normal Mode, 219 uH, 20%

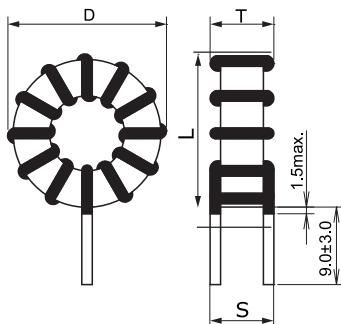

Dimensions

D	50.5mm MAX
L	50.5mm MAX
T	50.5mm MAX
LL	9mm +/-3mm
S	19mm NOM

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	60
Weight:	137 g

General Information

Series:	SHBC
Style:	Through-Hole
Features:	Low Core Loss, High Frequency Drive
RoHS:	Yes
Miscellaneous:	65 (K) Temperature Rise Max.

Specifications

Inductance:	219 uH
Inductance Tolerance:	20%
Current:	15 A
Temperature Range:	-40/+125°C
DC Resistance:	19.5 mOhms