


Geberit Mapress Stainless Steel T-piece with female thread (gas)



Example image

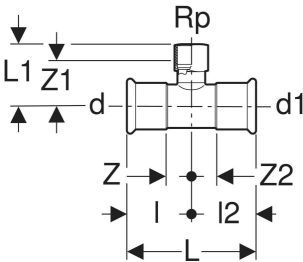

APPLICATION PURPOSES

- For natural gases
- For liquefied gases
- For biogases
- For natural and liquefied gases

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed
- Marked in yellow
- Seal ring made of HNBR, yellow
- LABS-free
- Pressing socket with yellow protection plug

TECHNICAL DATA

Product material CrNiMo steel 1.4401 (EN 10088)

INFO

- Fittings with screwing joints > 2" have a reduced operating pressure: MOP 0.1 / GT 0.1

Art. no.	DN	d, ø mm	Rp "	d1, ø mm	arc °	L cm	L1 cm	I cm	I2 cm	Z cm	Z1 cm	Z2 cm
34052	12 / 15 / 12	15	1/2	15	90	6.4	4	3.2	3.2	1.2	2.7	1.2
34053	15	18	1/2	18	90	6.8	4.2	3.4	3.4	1.4	2.9	1.4
34054	15 / 20 / 15	18	3/4	18	90	6.8	4.4	3.4	3.4	1.4	2.9	1.4
34055	20 / 15 / 20	22	1/2	22	90	7.4	4.3	3.7	3.7	1.6	3	1.6
34056	20	22	3/4	22	90	7.4	4.6	3.7	3.7	1.6	3.1	1.6

Art. no.	DN	d, ø mm	Rp "	d1, ø mm	arc °	L cm	L1 cm	I cm	l2 cm	z cm	z1 cm	z2 cm
34057	25 / 15 / 25	28	1/2	28	90	8.4	4.6	4.2	4.2	1.9	3.3	1.9
34058	25 / 20 / 25	28	3/4	28	90	8.4	4.9	4.2	4.2	1.9	3.4	1.9
34059	32 / 15 / 32	35	1/2	35	90	10	5	5	5	2.4	3.7	2.4
34060	32 / 20 / 32	35	3/4	35	90	10	5.3	5	5	2.4	3.8	2.4
34061	40 / 15 / 40	42	1/2	42	90	11.4	5.3	5.7	5.7	2.7	4	2.7
34126	40 / 20 / 40	42	3/4	42	90	11.4	5.6	5.7	5.7	2.7	4.1	2.7
34063	50 / 15 / 50	54	1/2	54	90	13.8	5.9	6.9	6.9	3.4	4.6	3.4
34264	50 / 20 / 50	54	3/4	54	90	13.8	6.2	6.9	6.9	3.4	4.7	3.4
34265	50	54	2	54	90	13.8	7.9	6.9	6.9	3.4	5.6	3.4
34266	65 / 20 / 65	76.1	3/4	76.1	90	23	7.4	11.5	11.5	6.2	5.9	6.2
34267	65 / 50 / 65	76.1	2	76.1	90	23	9.1	11.5	11.5	6.2	6.8	6.2
34268	80 / 20 / 80	88.9	3/4	88.9	90	26	8	13	13	7	6.5	7
34269	80 / 50 / 80	88.9	2	88.9	90	26	9.7	13	13	7	7.4	7

Art. no.	DN	d, ø mm	Rp "	d1, ø mm	arc °	L cm	L1 cm	l cm	l2 cm	z cm	z1 cm	z2 cm
34270	100 / 20 / 100	108	3/4	108	90	31	9	15.5	15.5	8	7.5	8
34271	100 / 50 / 100	108	2	108	90	31	10.7	15.5	15.5	8	8.4	8