

# PRODUCT DATASHEET

## WORK VAL 3POD 2x50 W 4000 K IP65

WORKLIGHT VALUE 3POD | Versatile LED worklight with tripod stand



### AREAS OF APPLICATION

- Renovation
- Garages
- Basement
- Workshops

### PRODUCT BENEFITS

- Foldable for easy storage
- Energy savings of up to 80% compared to halogen lamp worklights
- Semi-frosted, tempered glass cover for uniform illumination
- 3 years guarantee

### PRODUCT FEATURES

- "Plug and play" worklights with up to 9000 lm
- Rotation angle luminaire head: 360°, swiveling: 180°
- Die-cast aluminum housing with PC front cover
- Type of protection, luminaire head and housing: IP65, Type of protection, plug: IP44
- Height adjustment of tripod up to 1.8 m total height
- Quick-release fastener for adjustment of luminaire head angle
- Type E/F plug



**TECHNICAL DATA**

Electrical data

Nominal wattage	100.00 W
Operating mode	Integrated LED driver
Nominal voltage	220...240 V
Mains frequency	50/60 Hz
Power factor $\lambda$	> 0.90
Total harmonic distortion	< 20 %


Photometrical data

Color temperature	4000 K
Color rendering index Ra	$\geq 80$
Light color (designation)	Cool White
Luminous flux	9000 lm
Luminous efficacy	90 lm/W
Standard deviation of color matching	$\leq 6$ sdc <sub>m</sub>

Light technical data

Beam angle	110 °
------------	-------

— Dimensions & weight

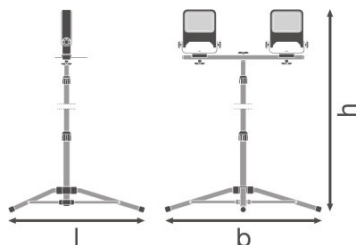

Length	680.0 mm
Width	780.0 mm
Height	1800 mm
Product weight	4800.00 g
Cable length	2000 mm

Colors & materials

Product color	Black
---------------	-------

<b>Housing color</b>	Black
<b>Body material</b>	Aluminum
<b>Cover material</b>	Glass

### Temperatures & operating conditions

<b>Ambient temperature range</b>	-20...+45 °C
----------------------------------	--------------

### Lifespan

<b>Number of switching cycles</b>	10000
<b>Lifespan L70/B50 at 25 °C</b>	30000 h

### Additional product data

<b>Mounting type</b>	Standing
<b>Mounting location</b>	Floor

### Capabilities

<b>Dimmable</b>	No
<b>Type of connection</b>	Protective contact Plug type
<b>LED module replaceable</b>	Not replaceable

### Certificates & standards

<b>Type of protection</b>	IP65 <sup>1)</sup>
<b>Protection class</b>	I
<b>Protection class IK (shock resistance)</b>	IK06
<b>Glow Wire Test according to IEC 60695-2-12</b>	650 °C
<b>Photobiological safety group EN62778</b>	RG 1
<b>Luminaire with limited surface temperature, class "D"</b>	No
<b>Standards</b>	CE/CB/EAC/RoHS



<sup>1)</sup> Luminaire head and housing IP65, plug IP44

### LOGISTICAL DATA

Product code	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Gross weight	Volume
4058075308879	Folding carton box 1	182 mm x 229 mm x 644 mm	5059.00 g	26.84 dm <sup>3</sup>
4058075308886	Shipping carton box 4	475 mm x 380 mm x 665 mm	21264.00 g	120.03 dm <sup>3</sup>

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

### ADDITIONAL CATALOG INFORMATION

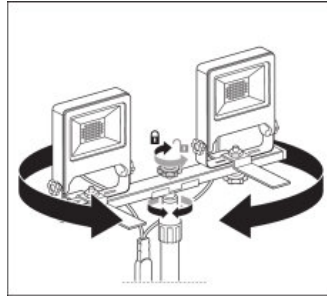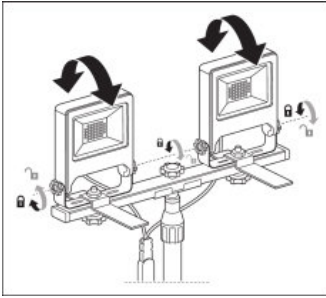


---

**REFERENCES / LINKS**

For Guarantee see

▶ [www.ledvance.com/guarantee](http://www.ledvance.com/guarantee)

---

**DISCLAIMER**

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.