


## xzcp1764I2

pre-wired connectors XZ - straight female - 7/8"16  
UN - 5 pins - cable PUR 2m

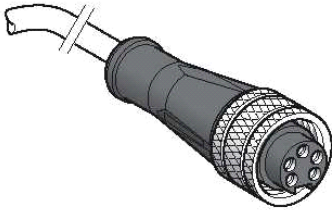

### Main

Accessory / separate part category	Cabling accessories
Accessory / separate part type	Pre-wired connectors
Series name	General purpose
Electrical connection	Straight female connector 7/8"16 UN, 5 pins (included earth pin)
Collar material	Metal
Status LED	Without
Cable length	2 m

### Complementary

Cable connector fixing	Screw-on
Cable outer diameter	5.9 mm
Cable composition	5 x 0.34 mm <sup>2</sup>
Wire insulation material	PUR
[Ue] rated operational voltage	250 V AC
[In] rated current	4 A
Contact resistance	<= 5000 µOhm
Insulating resistance	>= 1 GΩ
Product weight	0.185 kg

### Environment

IP degree of protection	IP67
Ambient air temperature for operation	-35...90 °C (static) -5...90 °C (flexing)
Ambient air temperature for storage	-35...100 °C

### Offer Sustainability

Sustainable offer status	Not Green Premium product
RoHS	Compliant - since 0726 - Schneider Electric declaration of conformity

The information provided in this documentation contains general descriptions and/or technical characteristics of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.