


## Datasheet

# NewRS 28V dc Wire Leads Magnetic Buzzer, $\geq 105\text{dB}$ Continuous, Slow & Fast Pulse

RS Stock 837-7850



### Dimensions: (mm)

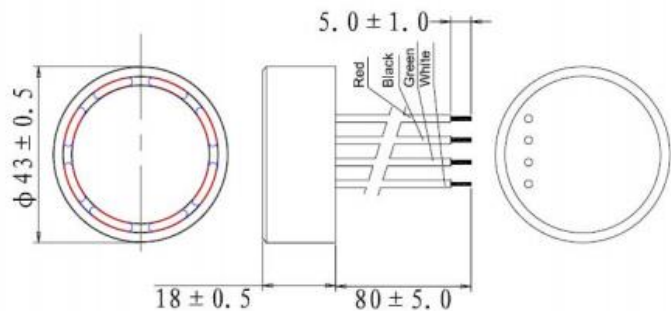

**Wiring Instruction:**  
 Red = positive supply  
 Black = continuous tone  
 Green = slow pulse  
 White = fast pulse

### Specifications

### ABI-046-RC

Rated voltage	12VDC
Operating voltage	6~28VDC
Rated current*	$\leq 25\text{mA}$
Sound output at 30cm*	$\geq 105\text{dB}$
Coil resistance	$2900\Omega \pm 500\text{Hz}$
Operating temperature	$-20 \sim +70^\circ\text{C}$
Storage temperature	$-30 \sim +80^\circ\text{C}$
Weight	20g

\*Value applying at rated voltage (DC)

#### Features

- ROHS compliant
- Multi tone sounder - continuous tone, slow and fast pulse
- Housing material: PBT
- Wire leads: UL1007 – AWG26

All data at 25°C unless otherwise specified