


Alphabetical Picture Part Number  
**SEARCH SEARCH SEARCH**

Go To Step Search™ Screen

**640905-1** -- 1 of 1 products

**Terminals and Splices**  
**FASTON Receptacles - Insulated**

General **INFO**  
Sales **INFO**  
Customer Drawings **SPECIFICATIONS**

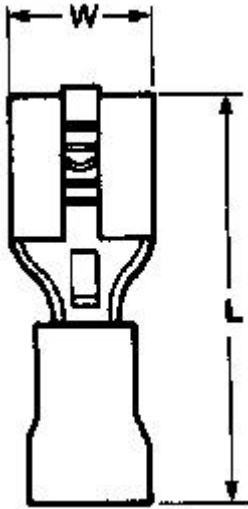

*Line art represents typical product only.*

<b><i>Searchable Features:</i></b>	
<b>AMP Proprietary Name</b>	PIDG
<b>Tab Fit</b>	.250 x .032 [6.35 x 0.81] in. [mm]
<b>Wire Range</b>	16-14 AWG [mm]
<b>Insulation Diameter</b>	.170 [4.32] Max. in. [mm]
<b>Material</b>	Brass
<b>Finish</b>	Tin
<b>Insertion Force</b>	Normal
<b>Dimple Type</b>	Dimple with wire stop
<b>Packaging Method</b>	Loose Piece
<b>Receptacle Style</b>	Straight
<b>Insulation Support</b>	Insulation Support
<b><i>Other Properties:</i></b>	
<b>Insulation</b>	Yes
<b>Color</b>	Blue
<b>RU (UL Component Program)</b>	Approved
<b>CSA Certified</b>	Approved
<b>Dim. W</b>	.300 [7.62] in. [mm]
<b>Dim. L</b>	.900 [22.86] Max. in. [mm]
<b>Stock Thickness</b>	.018 [0.46] in. [mm]
<b>Wire Range (CMA)</b>	2,050-5,180

---

[ [Main Menu](#) | [Help](#) | [Families](#) | [Registration](#) | [Feedback](#) ]  
[Top of Page](#)