



Brand of NTN corporation


## Technical data

### BBE60AUU

Standard ball bushings closed



#### VISUAL (S)

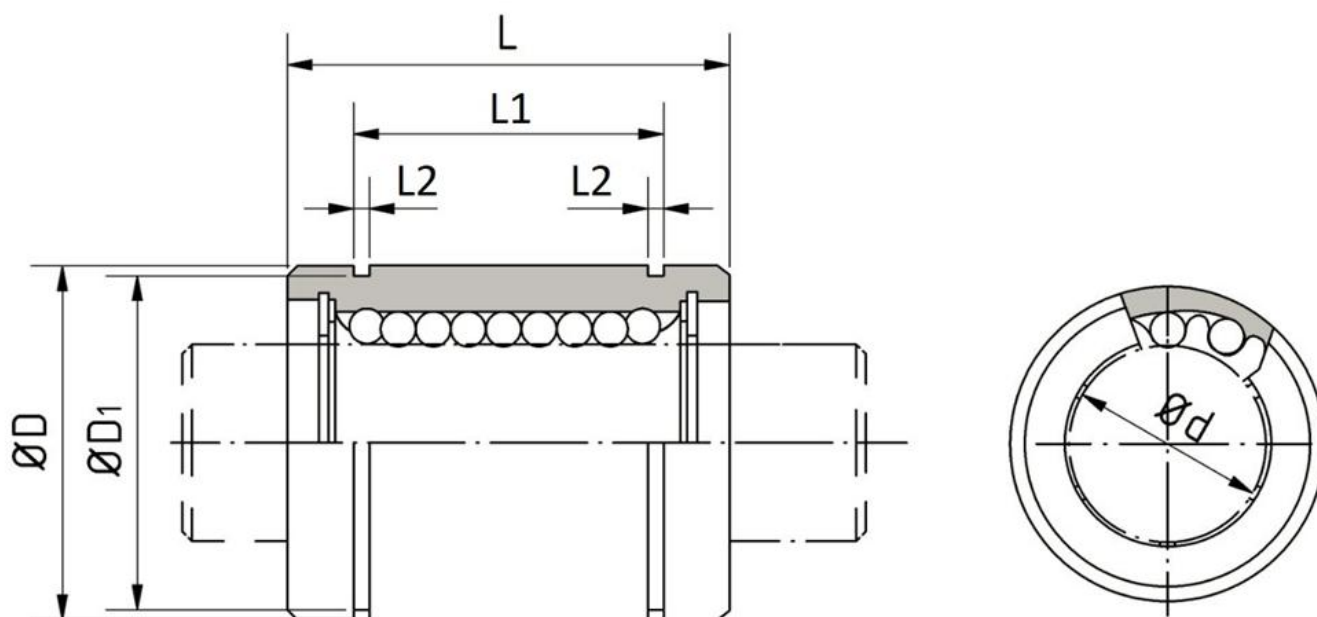

#### PRODUCT DEFINITION

|                                           |                                |
|-------------------------------------------|--------------------------------|
| Brand                                     | SNR                            |
| Design type                               | BBE                            |
| Ball bushings category                    | Standard ball bushings, closed |
| Standard                                  | ISO dimension                  |
| Number of seals                           | 2                              |
| Material outer cylinder or steel segments | 100Cr6                         |
| Material Cage                             | St15                           |
| Initial greasing                          | Non/No                         |
| d - Internal diameter                     | 60 mm                          |



#### NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

## PRODUCT DEFINITION

|                                        |              |
|----------------------------------------|--------------|
| <b>d - Internal diameter tolerance</b> | 0,013/-0,002 |
| <b>D - External diameter</b>           | 90 mm        |
| <b>D - External diameter tolerance</b> | 0/-0,015     |
| <b>L - Length</b>                      | 125 mm       |
| <b>L - Length tolerance</b>            | 0/-0,4       |
| <b>L1</b>                              | 101,7 mm     |
| <b>L1 tolerance</b>                    | 0/-0,4       |
| <b>D1 - Diameter</b>                   | 86,5 mm      |
| <b>L2</b>                              | 3,15 mm      |
| <b>Number of ball rows</b>             | 6            |
| <b>Mass</b>                            | 2,22 kg      |

## PRODUCT PERFORMANCE

|                                         |           |
|-----------------------------------------|-----------|
| <b>Cmin</b>                             | 6,086 kN  |
| <b>Cmax</b>                             | 7,79 kN   |
| <b>C0min</b>                            | 9,8 kN    |
| <b>C0max</b>                            | 12,544 kN |
| <b>Tmin - Min operating temperature</b> | -20 °C    |
| <b>Tmax - Max operating temperature</b> | 110 °C    |

## ESHOPDONOTDISPLAY

|                              |                            |
|------------------------------|----------------------------|
| <b>Reference</b>             | BBE60AUU                   |
| <b>Image</b>                 | BBE+BB_1.JPG, BBE+BB_3.JPG |
| <b>Send to Eshop</b>         | Yes                        |
| <b>Send to Paper Catalog</b> | Yes                        |



ESHOPDONOTDISPLAY

Tracepart

Oui/Yes

