

BDX – the range

Norton has a global reputation for its high quality and job focussed abrasive products.

BDX, the standard range for portable and fixed machines, offers the user excellent solutions for most applications at a fair price. The BDX range features a broad selection for steel/stainless steel and stone applications.

Diameter x thickness x hole

Safety pictograms

Field of application

Red speed stripe = 80 m/s


Maximum peripheral speed

Product specification

Product code: for use when ordering

European standard EN12413

oSa logo - The Organisation for Safety of Abrasives

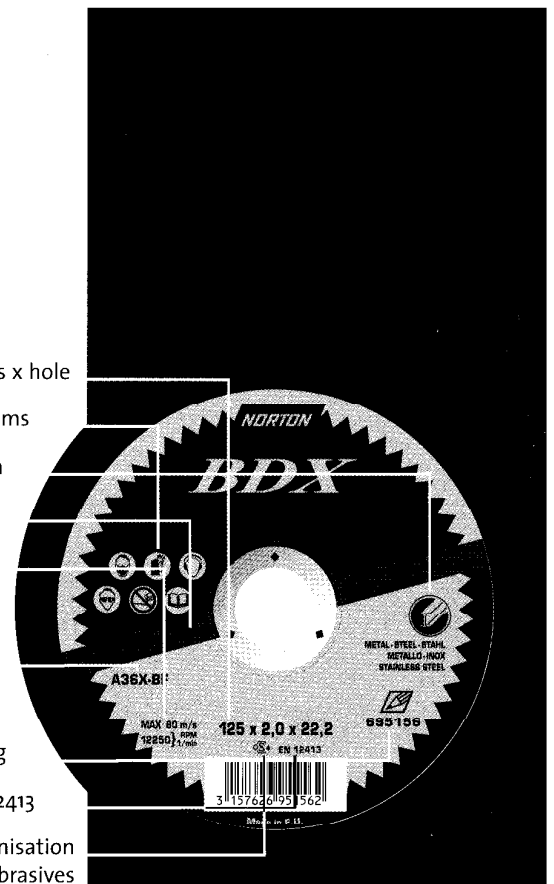

Product code	Type	Dimensions	Specification		EAN-code
--------------	------	------------	---------------	---	----------


Depressed centre cutting wheels for angle grinders

695045	42	100x2,5x16,0	BDX Metal	25	3157626950459
695056	42	115x2,5x22,2	BDX Metal	25	3157626950565
695070	42	125x2,5x22,2	BDX Metal	25	3157626950701
695076	42	150x2,5x22,2	BDX Metal	25	3157626950763
695082	42	180x2,5x22,2	BDX Metal	25	3157626950824
695144	42	230x2,5x22,2	BDX Metal	25	3157626951449
695049	42	100x3,2x16,0	BDX Metal	25	3157626950497
695061	42	115x3,2x22,2	BDX Metal	25	3157626950619
695072	42	125x3,2x22,2	BDX Metal	25	3157626950725
695078	42	150x3,2x22,2	BDX Metal	25	3157626950787
695084	42	180x3,2x22,2	BDX Metal	25	3157626950848
695146	42	230x3,2x22,2	BDX Metal	25	3157626951463
695048	42	100x2,5x16,0	BDX Stone	25	3157626950480
695060	42	115x2,5x22,2	BDX Stone	25	3157626950602
695071	42	125x2,5x22,2	BDX Stone	25	3157626950718
695077	42	150x2,5x22,2	BDX Stone	25	3157626950770
695083	42	180x2,5x22,2	BDX Stone	25	3157626950831
695145	42	230x2,5x22,2	BDX Stone	25	3157626951456
695051	42	100x3,2x16,0	BDX Stone	25	3157626950510
695063	42	115x3,2x22,2	BDX Stone	25	3157626950633
695073	42	125x3,2x22,2	BDX Stone	25	3157626950732
695079	42	150x3,2x22,2	BDX Stone	25	3157626950794
695085	42	180x3,2x22,2	BDX Stone	25	3157626950855
695147	42	230x3,2x22,2	BDX Stone	25	3157626951470

- BDX Metal
- steel/stainless steel
- high efficiency
- easy cutting



 
- BDX Stone
- stone/concrete
- high efficiency
- easy cutting






41


Type 41

Product code	Type	Dimensions	Specification		EAN-code
Straight cutting-off wheels for angle grinders					
767150	41	115x1,0x22,2	BDX Metal	25	3157627671506
649076	41	115x1,6x22,2	BDX Metal	25	3157626490764
767152	41	125x1,0x22,2	BDX Metal	25	3157627671520
649078	41	125x1,6x22,2	BDX Metal	25	3157626490788
386569	41	180x1,6x22,2	BDX Metal	25	3157623865695
386571	41	230x1,9x22,2	BDX Metal	25	3157623865718
696904	41	100x2,0x16,0	BDX Metal	25	3157626969048
695153	41	115x2,0x22,2	BDX Metal	25	3157626951531
695156	41	125x2,0x22,2	BDX Metal	25	3157626951562
695158	41	150x2,0x22,2	BDX Metal	25	3157626951586
695160	41	180x2,0x22,2	BDX Metal	25	3157626951609
695162	41	230x2,0x22,2	BDX Metal	25	3157626951623
695154	41	115x2,5x22,2	BDX Metal	25	3157626951548
695157	41	125x2,5x22,2	BDX Metal	25	3157626951579
695159	41	150x2,5x22,2	BDX Metal	25	3157626951593
695161	41	180x2,5x22,2	BDX Metal	25	3157626951616
695163	41	230x2,5x22,2	BDX Metal	25	3157626951630
363826	41	115x2,5x22,2	BDX Stone	25	3157623638268
363829	41	125x2,5x22,2	BDX Stone	25	3157623638299
363831	41	180x2,5x22,2	BDX Stone	25	3157623638312
363832	41	230x2,5x22,2	BDX Stone	25	3157623638329
301544	41	100x3,0x16,0	BDX Stone	25	3157623015441
301545	41	115x3,0x22,2	BDX Stone	25	3157623015458
301546	41	125x3,0x22,2	BDX Stone	25	3157623015465
301548	41	180x3,0x22,2	BDX Stone	25	3157623015489
301549	41	230x3,0x22,2	BDX Stone	25	3157623015496

 - BDX Metal
- steel/stainless steel
- high efficiency
- easy cutting



 - BDX Stone
- stone/concrete
- high efficiency
- easy cutting



Straight cutting-off wheels for chop saws

695171	41	300x2,8x25,4	BDX Metal	10	3157626951715
695172	41	350x3,0x25,4	BDX Metal	10	3157626951722
695173	41	400x3,0x25,4	BDX Metal	10	3157626951739


- BDX Metal
- steel/stainless steel
- high efficiency
- easy cutting



Straight cutting-off wheels for fixed machines

386576	41	300x3,5x22,2	BDX Metal	10	3157623865763
695168	41	300x3,5x25,4	BDX Metal	10	3157626951685
386577	41	300x3,5x32,0	BDX Metal	10	3157623865770
695169	41	350x4,5x25,4	BDX Metal	10	3157626951692
396795	41	350x4,5x30,0	BDX Metal	10	3157623967955
695170	41	400x4,5x25,4	BDX Metal	10	3157626951708
396797	41	400x4,5x40,0	BDX Metal	10	3157623967979

 - BDX Metal
- steel/stainless steel
- high efficiency
- easy cutting



41

Type 41





27 Type 27

Product code	Type	Dimensions	Specification		EAN-code
--------------	------	------------	---------------	---	----------

Depressed centre notching wheels for angle grinders

301536	27	100x4,0x16,0	BDX Metal	25	3157623015366
792302	27	115x4,0x22,2	BDX Metal	25	3157627923025
792303	27	125x4,0x22,2	BDX Metal	25	3157627923032
301540	27	180x4,0x22,2	BDX Metal	25	3157623015403
301543	27	230x4,0x22,2	BDX Metal	25	3157623015434

- BDX Metal
- steel/stainless steel
- fast material removal



Depressed centre grinding wheels for angle grinders

695052	27	100x6,5x16,0	BDX Metal	10	3157626950527
695064	27	115x6,5x22,2	BDX Metal	10	3157626950640
695074	27	125x6,5x22,2	BDX Metal	10	3157626950749
695080	27	150x6,5x22,2	BDX Metal	10	3157626950800
695086	27	180x6,5x22,2	BDX Metal	10	3157626950862
695150	27	230x6,5x22,2	BDX Metal	10	3157626951500

- BDX Metal
- steel/stainless steel
- fast material removal



695054	27	100x6,5x16,0	BDX Stone	10	3157626950541
695065	27	115x6,5x22,2	BDX Stone	10	3157626950657
695075	27	125x6,5x22,2	BDX Stone	10	3157626950756
695081	27	150x6,5x22,2	BDX Stone	10	3157626950817
695142	27	180x6,5x22,2	BDX Stone	10	3157626951425
695151	27	230x6,5x22,2	BDX Stone	10	3157626951517

- BDX Stone
- stone/concrete
- fast material removal



SAINT-GOBAIN
ABRASIVES

Saint-Gobain Abrasives Ltd.
Bridge Road East
Welwyn Garden City
Hertfordshire
AL7 1HZ
Tel: (01707) 323484
Fax: (01707) 325231

FEPA



The personal safety of workers using abrasive cutting and grinding wheels is the primary concern of Norton and Saint-Gobain Abrasives. All Norton abrasive wheels are developed, manufactured and safety tested in accordance with the European standard "EN12413 - Safety requirements for bonded abrasive products". Norton is a ISO registered manufacturer and Norton products are approved by the international safety standard oSa.