

Datasheet


RS Pro M12 male-M12 Female Angled

RS Pro: 877-1195



General Specification	
Rated Operational Voltage	250V
Current Rating	4A
Insulation Resistance	$\geq 100M\Omega$
Temperature Range	-25°C ... +75°C
Degree Of Protection	IP67
Material Specification	
Grip Material	PU
Contact	Cu-Zn
Contact Plating	Gold Plated
Contact Carrier	Nylon 66
O-Ring	Neoprene
Grip Colour	Black
Coupling Nut	Brass Nickel-Plated

Cable Specification	
Cable Length-L	2m
Cable Type	3 Core PVC Multi Strand
Sheath Colour	Black
Cross Section of Wire	0.34sq. mm
Core Dia	As per Manufacturer Specs.
Cable Dia	As per Manufacturer Specs.

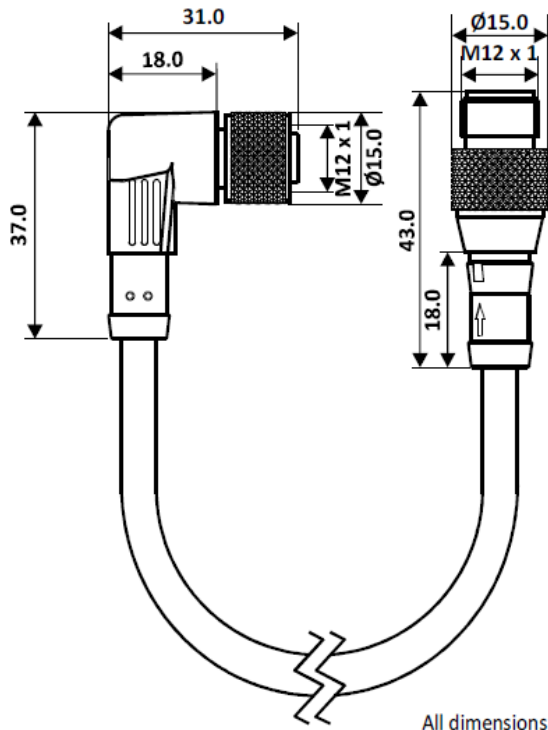

All dimensions are in mm.

Pin Assignment

