

Pin busbar, 16 mm<sup>2</sup> connection: 2x3x (1-phase+N) touch-safe


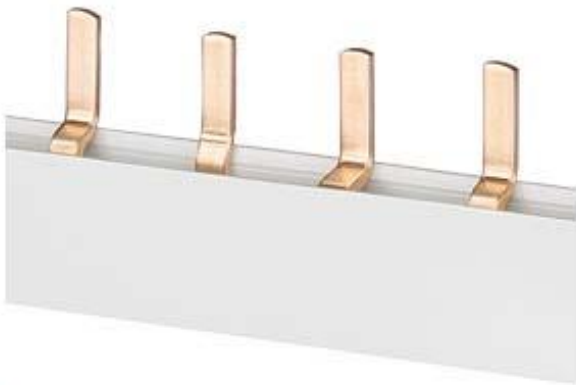


Figure similar

Model	
Product brand name	SENTRON
Electricity	
Continuous current / rated value	80 A
Product details	
Product feature / insulated	Yes
Connections	
Type of electrical connection	Pin
Mechanical Design	
Length	210 mm
Net weight	123.02 g
Certificates	

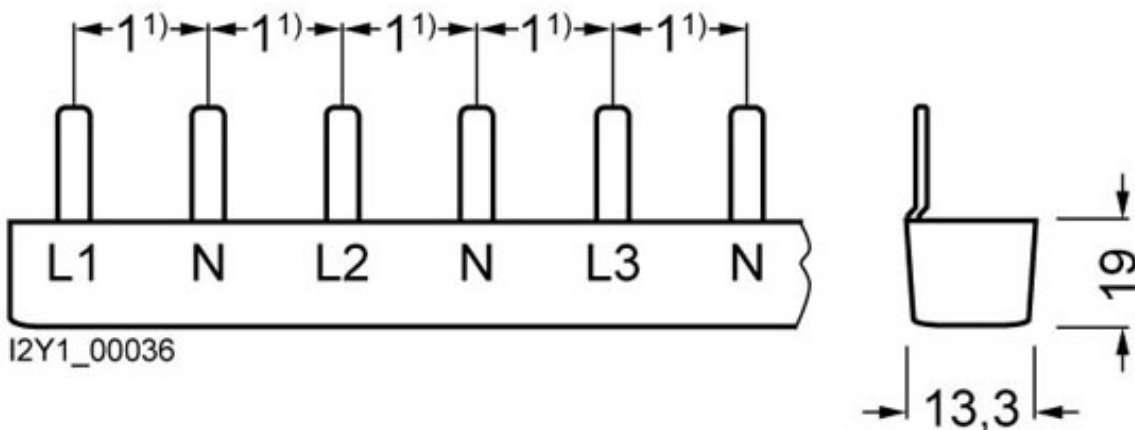

EG-Konf.

[Miscellaneous](#)**Further information****Information- and Downloadcenter (Catalogs, Brochures,...)**<http://www.siemens.com/lowvoltage/catalogs>**Industry Mall (Online ordering system)**<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=5ST3653>**Service&Support (Manuals, Certificates, Characteristics, FAQs,...)**<https://support.industry.siemens.com/cs/ww/en/ps/5ST3653>**Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)**[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=5ST3653](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=5ST3653)**CAX-Online-Generator**<http://www.siemens.com/cax>**Tender specifications**<http://www.siemens.com/specifications>

<sup>1)</sup> Pin spacings in MW (Modular widths, 1 MW = 18 mm).