

---

## 7528

Lamps with metal bases for cars



---

### Product benefits

- Wide product range
- Reliable quality

---

### Product features

- Original spare parts

# Product datasheet

## Technical data



### Electrical data

Power input	25 / 6 W
Nominal voltage	12.0 V
Power input tolerance	$\pm 6 / \pm 10$ %
Test voltage	13.5 / 13.5 V

### Photometrical data

Luminous flux	440/35 lm
Luminous flux tolerance	$\pm 15 / \pm 20$ %

### Dimensions & weight

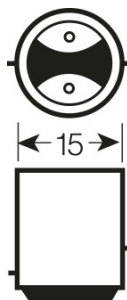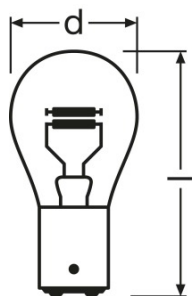

Length	52.5 mm
Diameter	26.5 mm

### Lifespan

Lifespan B3	180 / 1250 h <sup>1)</sup>
Lifespan Tc	290 / 4000 h <sup>1)</sup>

<sup>1)</sup> Filament 1 / Filament 2

### Additional product data

Base (standard designation)	BAY15d
-----------------------------	--------

### Certificates & standards

ECE category	P21/5W
Approval marks – approval	E1 approval

### Country specific categorizations

## Product datasheet

<b>Order reference</b>	7528 21/5W 12V
------------------------	----------------

---

### Country specific information

<b>Product code</b>	<b>METEL code</b>	<b>SEG number</b>	<b>STK-Number</b>	<b>UK Org</b>
4050300838069	OSRA7528	8328084	-	-

## Product datasheet

---

### Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4050300838069	7528	Unpacked 1	68 mm x 31 mm x 33 mm	0.07 dm <sup>3</sup>	28.83 g
4050300525129	7528	Folding carton box 10	79 mm x 54 mm x 123 mm	0.52 dm <sup>3</sup>	127.00 g
4008321091055	7528	Shipping carton box 50	273 mm x 65 mm x 145 mm	2.57 dm <sup>3</sup>	685.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

---

### Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.