 


# LED Signal Tower

## Features


- Light and acoustic functionality integrated in a single device
- Maximum electrical safety thanks to dedicated components
- Low consumption, zero maintenance required and maximum resistance to vibrations thanks to LED technology
- Multifunction light outputs
- Quick and easy assembly and installation




## Specification

Body Material	Polycarbonate (PC)
Ring Material	Polycarbonate (PC)
Luminous Source	N°4 LED
Available Colours	Red / Green / Orange
Voltage	24 VAC/VDC
Operation	∞
Current Consumption	190 mA
Light Output	<div><div><div></div><div></div><div></div></div><div>ALL COLOUR Cd(p)</div><div><div>3</div><div>2</div><div>1</div></div></div>
Light Effect	Continuous - Flashing
Protection Rating	IP54
Operating Temperature	-30 ... 50°C
Vibrations	INDUSTRIAL CEI 60068-2-6 SINE
Mounting	Base Mount
Acoustic Output	77 dB(A) 1m
Sound Effect	Dual Tone 800 Hz / 1 kHz

## Drawing

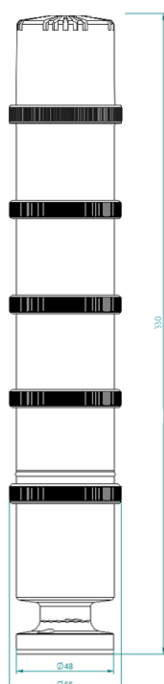

## Electrical Wiring

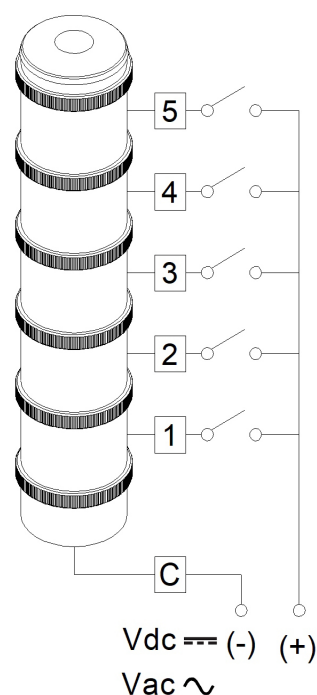

Art. Nr.  
RND 430-00039