




**Part Number :** [732762360](#)

**Product Description :** N Plug, Straight, Crimp, RG-141, RG303 and RG-58 Cable, Brass Body, Nickel (Ni) Plated, One Piece Per Bag, 50 Ohms

**Series Number :** 73276

**Status :** Active

**Product Category :** RF / Coaxial Connectors

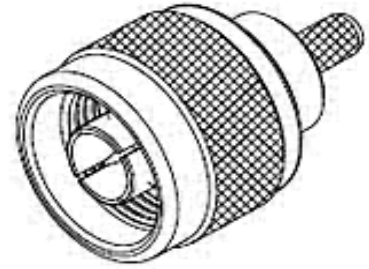

---

## Documents & Resources

### Drawings

[732762360 sd.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Contains Lead per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

### Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

---

## Part Details

### General

Status	Active
Category	RF / Coaxial Connectors
Series	73276
Description	N Plug, Straight, Crimp, RG-141, RG303 and RG-58 Cable, Brass Body, Nickel (Ni) Plated, One Piece Per Bag, 50 Ohms
Product Name	N
Style	Cable
Type	Medium
UPC	884982643222

### Electrical

Frequency	11 GHz
Impedance	50Ω
Power / Voltage	VOLTAGE: 1000 Vrms@Sea Level

### Physical

Cable Attachment	Crimp
Gender	Plug
Keying to Mating Part	N/A
Net Weight	33.072/g
Orientation	Straight
Packaging Type	Individual Bag
Panel Mount	No
Panel Mount Method	N/A
PCB Mounting	N/A
Reverse Polar	No
Wire/Cable Type	RG-58, RG-141, RG-303, LMR-195

