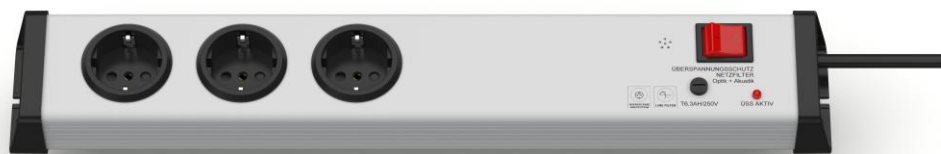


# Overvoltage protection line filter socket strip 3-fold with switch

Item-No.: 0207x00032301 (1,5 m cord) | 0207x00032303 (3 m cord)



Robust plastic, grey

Built-in sockets (90° rotated), round

Extra large space in between sockets 64 mm

1,5 m power cord and angle plug (optional with 3 m power cord)

Expanded contact protection by using a shutter

End caps with mounting possibility and spare fuse

Optical function display and acoustic fault message

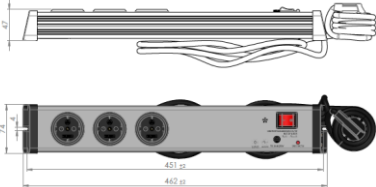
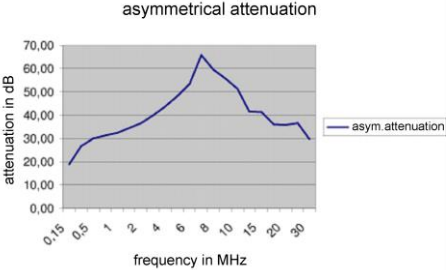
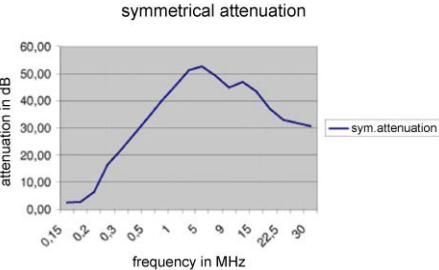
Line filter as protection against high-frequency interference with the network

EHMANN advantage - the connected devices will remain in operation after release of overvoltage protection



## Overvoltage protection line filter socket strip 3-fold with switch

### Technical data

| 3.600 W<br>Power                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                   | 230 V ~ (+/- 10%) / 50 Hz<br>Rated voltage                                           | 16 A<br>Rated current                                                                                                                                                                                                                                       |
|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| <p>Power Cord: H05VV-F 3G 1,5 mm<sup>2</sup></p> <p>Plug: CEE 7/7 plug Type EF, angled</p> <p>Sockets: earthing contact Type F</p> <p>Switch: 2-pole, illuminated</p> <p>Consumption per switch: &lt; 0,5 W</p> <p>Voltage U<sub>n</sub>: 230 V~</p> <p>Max. continuous operation voltage U<sub>c</sub>: 255 V~</p> <p>U<sub>oc</sub>: 5000 V</p> <p>Protection level Up: L-N &lt; 1,0kV - L/N-PE &lt; 1,5kV</p> <p>I<sub>max</sub> (8/20): 6,5 kA</p> <p>Fuse: T6,3AH/250 V</p> <p>SPD according to EN 61643-11: Typ3</p> <p>Consumption overvoltage protection: &lt; 0,1 W</p>  <p>(similar illustration)</p> |                                                                                      |    |
|                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |  |                                                                                                                                                                                                                                                             |
| <p>Item-No. 0207x00032301 (1,5 m cord)</p> <p>Item-No. 0207x00032303 (3 m cord)</p>                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                | <p>EAN 4012096026303</p> <p>EAN 4012096026310</p> <p>PU 10</p> <p>PU 10</p>          | <p>462 x 74 x 47 mm<br/>Dimensions (L x W x H)</p> <p>451 mm<br/>Fixing Dimension</p>                                                                                                                                                                       |