


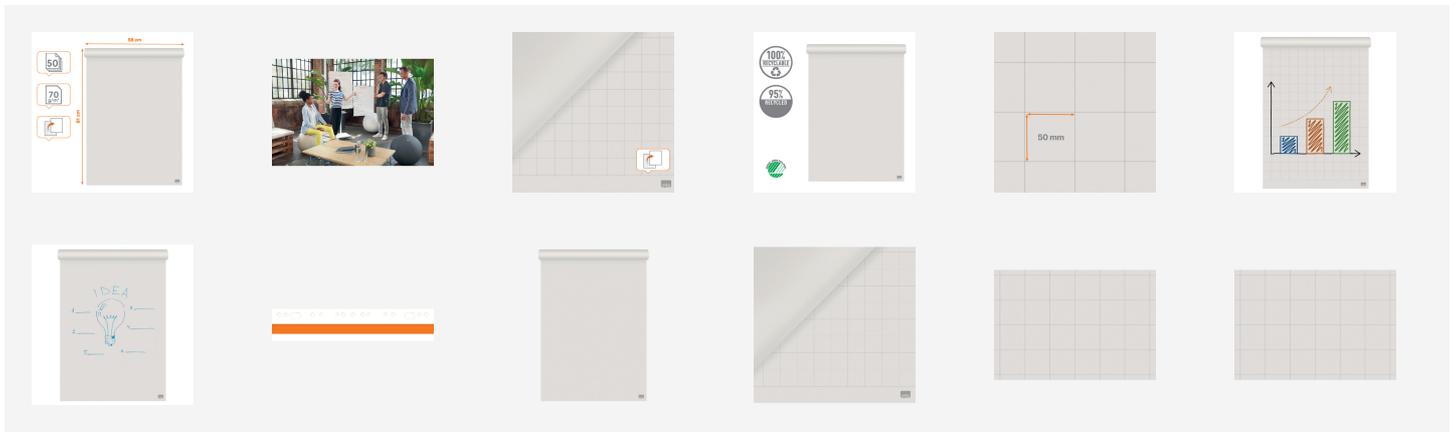

Nobo Recycled Flipchart Pad 58x81cm, Dual-Sided Plain or Gridded Paper, 50 Sheet, 70g/m², 1 Pack, Rolled

Recycled flipchart pad with dual-sided plain or gridded 70g/m² paper features a strong binder for easy use and to keep pages secure. High quality smooth paper is perforated for easy tear away when needed and is pre-punched with 15 holes allowing it to fit on most flipchart easels, making it the perfect tool for meetings and presentations. The high opacity paper allows the ink to stand out on page and helps prevent the ink from bleeding through on the reverse side. Overall 95% recycled content, 100% recyclable and age resistant, helping the paper stay clean and whiter for longer. Nordic Swan Certified. Flipchart paper size 58x81cm.



Attributes

- Dual-sided plain or gridded 70g/m² paper featuring a strong paper binder for easy use. Grid size 50mm
- High opacity paper allows the ink to stand out and helps prevent the ink from bleeding through on the reverse side.
- High quality paper is perforated and is pre-punched with 15 holes allowing it to fit on most flipchart easels.
- Paper sourced from responsibly managed European forests. Overall 95% recycled content, 100% recyclable and Nordic Swan certified.
- Age resistant, helping paper to stay clean and white and printed using solvent-free, water-based inks.
- Flipchart paper size 58x81cm, 50 sheets. Pack of 1, rolled, plastic free packaging.



Specifications

Number	1915659
Colour	-----
Dimensions (W x H x D)	580 x 810 x 6 mm
Weight	1723 g
Pallet quantity	72
EAN code	5028252641289