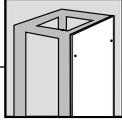
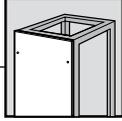
 
 
 


PROLINE® External Components for Modular Enclosures

Selection Matrix: Doors, Covers and Sides 

Steel Sides, Covers and Door Options

Single-Bay PROLINE Frame									
A	B	C	Solid Side ^a	Solid Cover ^a	Solid Door ^a	Door with Polycarbonate Window	Door with Safety Glass Window	Dress Frame	Disconnect Door System ^b
700	600	600	PSS76	PCS76	PDS76R	PDW76	PDWG76	PDF76	
700	800	600	PSS76	PCS78	PDS78R	PDW78	PDWG78		
1400	600	600	PSS146	PCS146	PDS146	PDW146	PDWG146	PDF146	
1400	800	500	PSS145	PCS148	PDS148	PDW148	PDWG148		
1400	800	800	PSS148	PCS148	PDS148	PDW148	PDWG148		
1600	600	400	PSS164	PCS166	PDS166	PDW166	PDWG166	PDF166	
1600	600	600	PSS166	PCS166	PDS166	PDW166	PDWG166	PDF166	
1600	600	800	PSS168	PCS166	PDS166	PDW166	PDWG166	PDF166	
1600	800	600	PSS166	PCS168	PDS168	PDW168	PDWG168		PTDDC168
1600	800	800	PSS168	PCS168	PDS168	PDW168	PDWG168		PTDDC168
1800	600	600	PSS186	PCS186	PDS186	PDW186	PDWG186	PDF186	
1800	600	800	PSS188	PCS186	PDS186	PDW186	PDWG186	PDF186	
1800	800	400	PSS184	PCS188	PDS188	PDW188	PDWG188		PTDDC188
1800	800	500	PSS185	PCS188	PDS188	PDW188	PDWG188		PTDDC188
1800	800	600	PSS186	PCS188	PDS188	PDW188	PDWG188		PTDDC188
1800	800	800	PSS188	PCS188	PDS188	PDW188	PDWG188		PTDDC188
1800	1000	500	PSS185	PCS1810	PDS1810				PTDDC1810
1800	1000	600	PSS186	PCS1810	PDS1810				PTDDC1810
1800	1000	800	PSS188	PCS1810	PDS1810				PTDDC1810
2000	600	400	PSS204	PCS206	PDS206	PDW206	PDWG206	PDF206	
2000	400	500	PSS205	PCS204	PDS204				
2000	600	500	PSS205	PCS206	PDS206	PDW206	PDWG206	PDF206	
2000	400	600	PSS206	PCS204	PDS204				
2000	600	600	PSS206	PCS206	PDS206	PDW206	PDWG206	PDF206	
2000	600	800	PSS208	PCS206	PDS206	PDW206	PDWG206	PDF206	
2000	700	600	PSS206	PCS207	PDS207	PDW207	PDWG207		
2000	700	800	PSS208	PCS207	PDS207	PDW207	PDWG207		
2000	800	400	PSS204	PCS208	PDS208	PDW208	PDWG208		PTDDC208
2000	800	500	PSS205	PCS208	PDS208	PDW208	PDWG208		PTDDC208
2000	800	600	PSS206	PCS208	PDS208	PDW208	PDWG208		PTDDC208
2000	800	800	PSS208	PCS208	PDS208	PDW208	PDWG208		PTDDC208
2000	800	900	PSS209	PCS208	PDS208	PDW208	PDWG208		PTDDC208
2000	1000	500	PSS205	PCS2010	PDS2010				PTDDC2010
2000	1000	600	PSS206	PCS2010	PDS2010				PTDDC2010
2000	1000	800	PSS208	PCS2010	PDS2010				PTDDC2010
2200	600	600	PSS226	PCS226	PDS226	PDW226	PDWG226	PDF226	
2200	600	800	PSS228	PCS226	PDS226	PDW226	PDWG226	PDF226	
2200	700	800	PSS228	PCS227	PDS227	PDW227	PDWG227		
2200	700	900	PSS229	PCS227	PDS227	PDW227	PDWG227		
2200	800	600	PSS226	PCS228	PDS228	PDW228	PDWG228		
2200	800	800	PSS228	PCS228	PDS228	PDW228	PDWG228		
2200	1000	500	PSS225	PCS2210	PDS2210				
2200	1000	600	PSS226	PCS2210	PDS2210				

^aAlso available with EMC shielding.

^bCatalog numbers shown in matrix are for doors with right-hand provision. Doors with left-hand and large cutout provisions also are available.