



Model Number


V95-W-2M-PVC

Female connector, 7/8", 5-pin, PVC cable

Features

- Immunity to vibration due to the O-ring which is integrated in the coupling nut
- Suitable for 2-, 3- and 4-wire technology

Dimensions

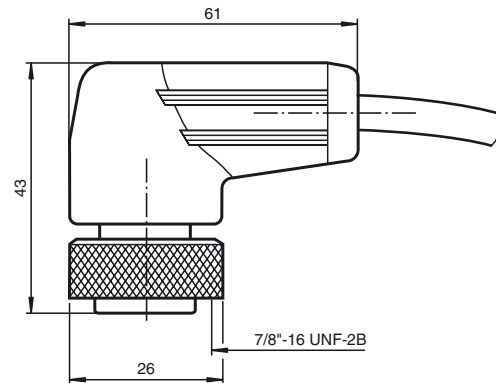

Technical data

General specifications

Number of pins	5
Connection 1	female connector
Construction type 1	right angle
Threading 1	7/8"
Connection 2	cable end

Electrical specifications

Operating voltage	U _B	max. 600 V
Operating current		max. 8 A

Ambient conditions

Ambient temperature	-40 ... 90 °C (-40 ... 194 °F)
---------------------	--------------------------------

Mechanical specifications

Protection degree	IP68/NEMA 6P only when properly seated
Connection	1 x 7/8"-16 UN connector, right-angled Cable: flexible lead

Material

Contacts	CuZn, nickel-plated
Contact surface	Au
Body	PUR, yellow
Cable	PVC
Slotted nut	Alu, black coated
Core insulation	PVC
Cable	16 AWG - UL STOW, copper lead
Color	yellow
Cores	5 x 1.5 mm ² (16 AWG)
Length	L 2 m

Electrical connection

