

Honeywell



Hobbs brand products are now a part of Honeywell.

Vehicle Controls *Hobbs*

Hobbs Key Switches


Screw Terminal Version

The screw terminal version provides more switching options as well as contacts that increase the electrical ratings.

Specifications:	
Design Electrical Ratings:	12 VDC, 20 Amps 24 VDC, 10 Amps 48 VDC, 4 Amps
Operating Temperature Range:	-40°C to +85°C
Cycle Life At Design Electrical Load:	25,000 Cycles



3 Position

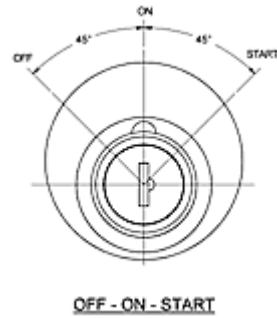

Part # 84829

(key removable in OFF position)

Optional Features & Benefits:

- Wire harness
- Key removable in multiple positions
- Rubber key cover for environmental protection
- Match existing key codes
- Custom molding of rubber key cover

