

Technical data


WS81118

Thrust washer



Needle roller bearing, thrust needle roller bearing, inner ring

VISUAL (S)

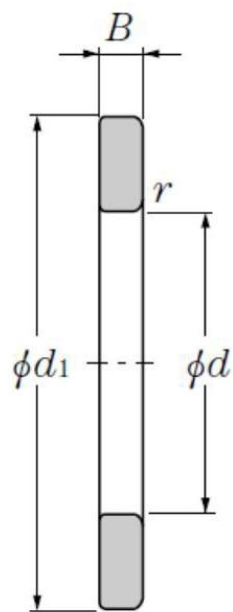

PRODUCT DEFINITION

Brand	NTN
d - Bore diameter of support washer IR - WS	90 mm
d1 - External diameter of support washer IR - WS	120 mm
B - Ring thickness	6,5 mm
rs - Min fillet radius	1 mm
Bearing ring (inner ring) WS mass	0,25 kg

PRODUCT PERFORMANCE

Tmin - Min operating temperature	253,15 °K
----------------------------------	-----------



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT PERFORMANCE

Tmax - Max operating temperature	393,15 °K
----------------------------------	-----------

