

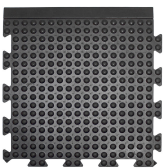
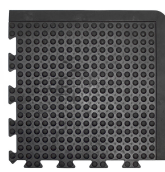
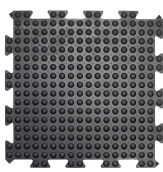
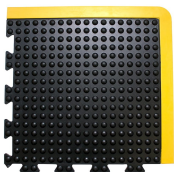
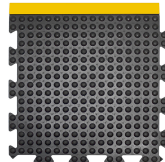


## Bubblemat Connect

Interlocking tiles with high anti-fatigue properties

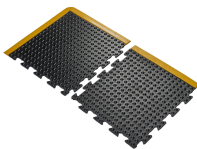

- Durable anti-fatigue matting system.
- Raised bubbled surface to stimulate blood circulation and reduction of fatigue.
- Interlocking system provides flexibility in the type of shape that can be created.
- Soft but sturdy rubber material offers protection from adverse effects from cold, hard concrete floors.
- Rubber is naturally slip resistant.

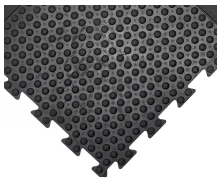

### Parts

Part Number	Size	Colour	Weight (kg)
-------------	------	--------	-------------

### Technical Specifications

Material	Natural rubber
----------	----------------

Recycled	33 - 43
----------	---------

Part Number	Size	Colour	Weight (kg)
BF010007	50 cm x 50 cm	Black	2.05
BF010008	50 cm x 50 cm	Black	2.05
BF010009	50 cm x 50 cm	Black	2.05
BF010708	50 cm x 50 cm	Black/Yellow	2.05
BF010709	50 cm x 50 cm	Black/Yellow	2.05

<b>Material Content %</b>	
<b>Surface Finish</b>	Bubble
<b>Product Height</b>	13.5 mm
<b>Product Weight</b>	5.75 kg
<b>Min. Operating Temperature</b>	-30°C
<b>Max. Operating Temperature</b>	+50°C
<b>Resistance to Chemicals</b>	Not resistant to fat and mineral oil
<b>Environmental Resistance</b>	Suitable for dry indoor environments
<b>UV Resistance</b>	Yes
<b>Installation Method</b>	Loose lay interlocking mats
<b>Cleaning Method</b>	Use a high pressure hose (not exceeding 60psi) to remove the dirt and debris on the mats. For best results use a mild detergent (pH 4.0-9.0) to clean the mats. Do not use steam or degreasers or caustic chemicals. Do not mechanically scrub the mats.
<b>COO (Country of Origin)</b>	LK
<b>Tensile Strength</b>	3 MPa
<b>Elongation</b>	250%
<b>Manufacturing process</b>	Compression moulding

Get in touch | To order FREE samples or arrange a site visit please call +44 (0)1788 228 555 or email [sales@cobaeurope.com](mailto:sales@cobaeurope.com)

[www.cobaeurope.com](http://www.cobaeurope.com)