


554258 ADNGF-50-5-P-A Compact cylinder - Series from 05-2023

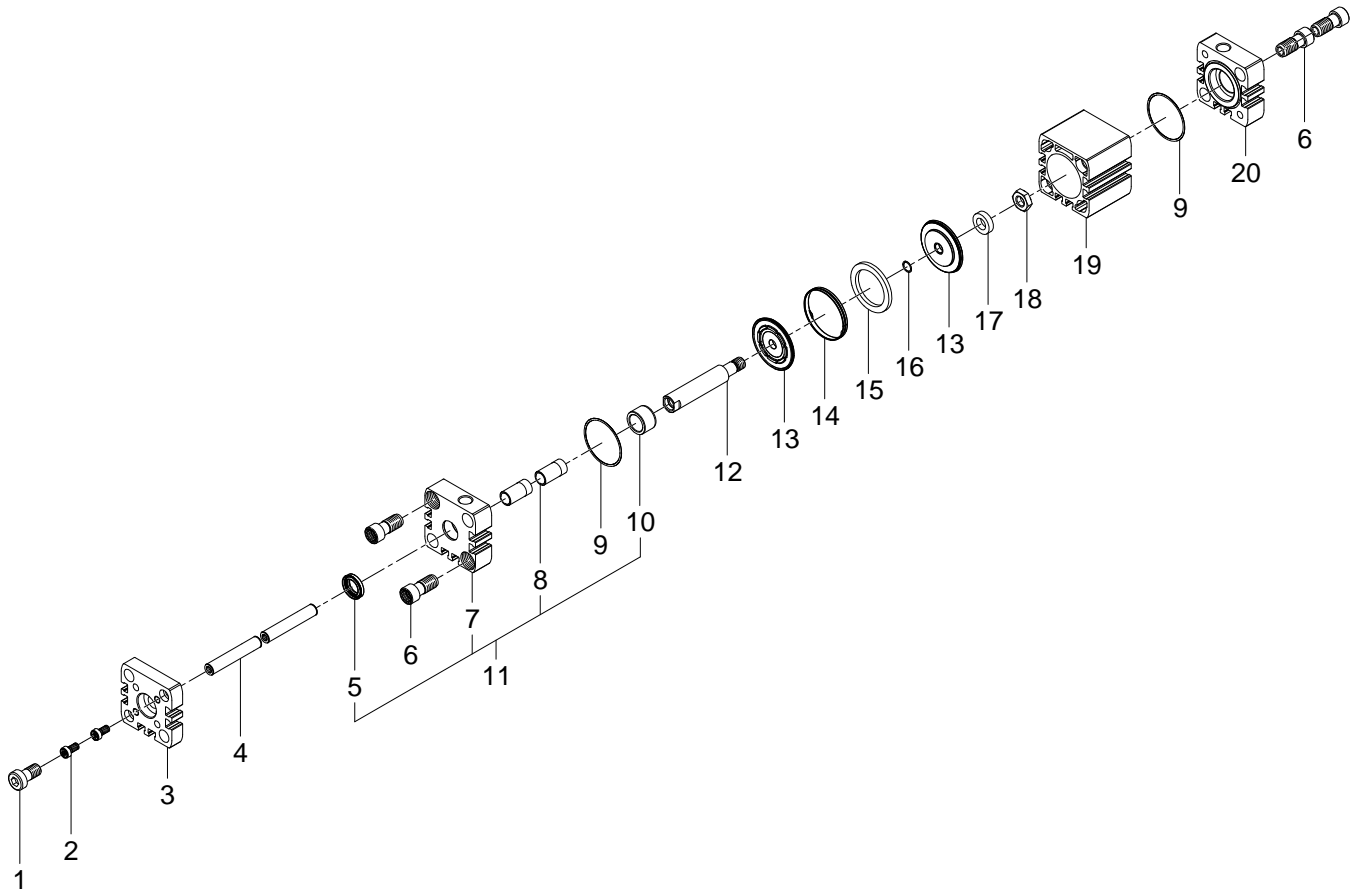

554258 ADNGF-50-5-P-A Compact cylinder - Series from 05-2023

Pos.	Part no.	Type	Note	Qty.	Unit
A	673625	ADN-50-P-A Set of wearing parts	Spare parts: 5, 9, 13, 14, 16	1	PC
1	774363	DIN 6912-M10X20-8.8 Socket head screw	Tightening torque 20 Nm / 14.8 lbf ft Use locking compound 8181258 CYBERBOND TI 7680	1	PC
2	207729	DIN 7984-M5X10-8.8 Socket head screw	Tightening torque 4.6 Nm / 3.4 lbf ft Use locking compound 8181258 CYBERBOND TI 7680	2	PC
3	8153514	ADNGF-50 Moment compensator		1	PC
4	8153435	ADNGF-50-X- Guide rod		2	PC
5	369543	WIFC1-16X20,5X4-TPE-U Wiper seal	Lubricate with 684474 LUB-KC1 during assembly	1	PC
6	658857	ADN-50/63 flange screw	Tightening torque 35 Nm / 25.8 lbf ft Use locking compound 8181258 CYBERBOND TI 7680	4	PC
7		ADNGF-50 Bearing cap	Not available separately, see position 11	1	PC
8		PSM-1012-15 Plain bearing	Not available separately, see position 11	2	PC
9		B-50X1,2-N-NBR70 O-ring ISO3601	Lubricate with 684474 LUB-KC1 during assembly Not available separately, see position A	2	PC
10		ADN-50/63 Bearing	Not available separately, see position 11	1	PC
11	8141772	ADNGF-50 Bearing cap module		1	PC
12	683597	ADN-50- - Piston rod	When ordering please specify the configuration (see type plate)	1	PC
13		BA-K01D-050 Piston module	Not available separately, see position A	2	PC
14		BA-K01F-050 Guiding band	Not available separately, see position A	1	PC
15	358739	46,6X38,2X4,6BA-K01M-050 Ring magnet		1	PC
16		B-11,5X1,5-N-NBR75 O-ring ISO3601	Not available separately, see position A	1	PC
17	356376	13X20X4-1.0715 Ring		1	PC
18	203968	DIN 439-B-M12X1,25-04 Hex nut	Tightening torque 30 Nm / 22.1 lbf ft Use locking compound 8181258 CYBERBOND TI 7680	1	PC
19		ADN-50-X- Cylinder barrel	Lubricate with 684474 LUB-KC1 during assembly Not available	1	PC
20	1305676	ADN-50 End cap		1	PC