



Datasheet

Stock No: 712-5323

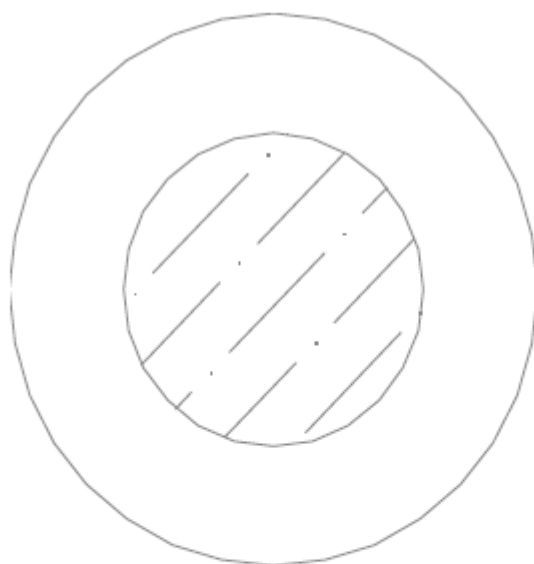
ENGLISH

# RS Pro Yellow Equipment Wire, 0.28mm<sup>2</sup> CSA, 1000 V 1.8 A 23 AWG, 100m



## Cable Construction

|                          |                      |
|--------------------------|----------------------|
| <b>Conductor</b>         | <b>Tinned Copper</b> |
| square(mm <sup>2</sup> ) | 0.28                 |
| Construction             | T0.60±0.01           |
| Standard Dia.(mm)        | 0.60                 |
| <b>Insulation</b>        | <b>PVC</b>           |
| Thickness                | 0.3                  |
| Insulation Dia.(±0.1mm)  | 1.20                 |


**Electrical Characteristics**

|  |      |
|--|------|
| Max.Conductor DC Resistance at 20 °C ( $\Omega$ /Km)   | <67  |
| Min.Insulation DC Resistance at 20 °C (M $\Omega$ *Km) | 200  |
| Rated Temperature(°C)                                  | 70   |
| Rated Voltage (V)                                      | 1000 |