


900/...

1/4" female and male drive extension bars

1/4"

UNI/ISO 3316 DIN 3123

	art.	L mm	Ø mm	□	■	g
009000818	900/20	50	11,5	1/4	1/4	20
009000819	900/20L	100	11,5	1/4	1/4	44
009000822	900/21	150	11,5	1/4	1/4	64
009000823	900/22	250	11,5	1/4	1/4	108
009000824	900/23	350	11,5	1/4	1/4	147

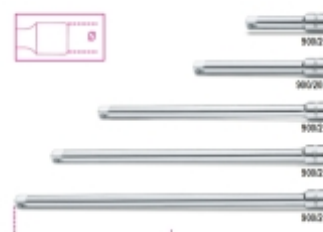

L