

Actuator

61-0059.0

Distribution by
Rs-online



<https://rs-online.eao.com/p/61-0059.0>

Your product:



61-0059.0 Actuator

FRONT

Front dimension:	24 mm x 24 mm
Front form:	Square
Front bezel colour:	Black
Front bezel material:	Plastic

MOUNTING

Mounting type:	Panel mounting
----------------	----------------

MECHANICAL CHARACTERISTIC

Tightening torque:	Max. 0.5 Nm
Weight:	0.005 kg

AMBIENT CONDITION

IP Protection:	IP40 rear side, according to EN IEC 60529, IP67 front side, according to EN IEC 60529
Operating temperature:	- 25 °C ... + 55 °C
Storage temperature:	- 40 °C ... + 85 °C

CERTIFICATE

REACH:	REACH compliant
RoHS:	RoHS compliant

OTHER

Short Description: Actuator, 24 mm x 24 mm, Square, Black, Plastic


Dimension: 24 mm x 24 mm

Internal size: 20 mm x 20 mm


Housing colour: Black

Housing material: Plastic, according to UL 94 V0, self-extinguishing

Wiring diagrams:

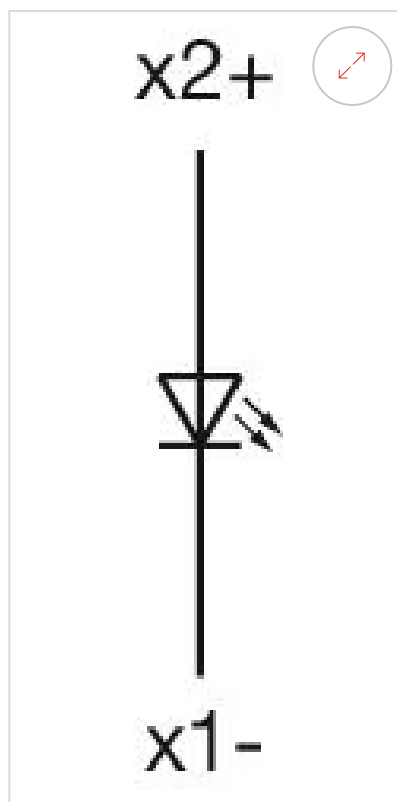

Mounting cut-outs:

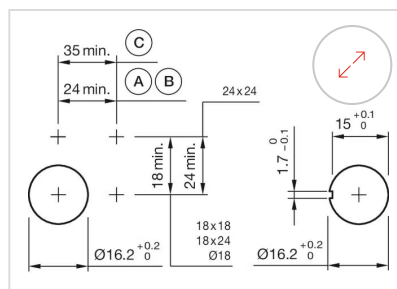


A = Solder/Plug-in terminal 2.8 mm x 0.5 mm

B = Solder terminal

C = Screw terminal

Dimension drawings:

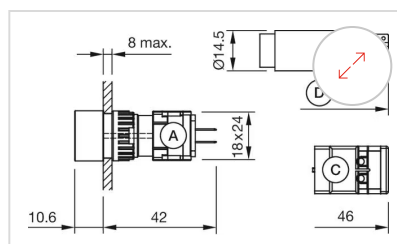

A = Plug-in terminal 2.8 mm x 0.5 mm

B = Solder terminal

C = Screw terminal

D = Flasher

E = Slow-make switching element

F = Snap-action switching element

