

**6.3 (1/4") SQUARE DRIVE**

6.3 1/4" 6.3 1/4"

[www.gedore.com](http://www.gedore.com)


**RATCHETS 6.3 (1/4")**

**2093 U-20**

**REVERSIBLE RATCHET 1/4"**

- Acc. to DIN 3122, ISO 3315
- Small, drop shaped head for confined areas
- Fine-toothed, with lever change and push-button release
- Non-slip 2-component handle with hanging hole
- For hand-operated sockets and accessories with square drive as per DIN 3120 - C 6.3, ISO 1174, ball locking device
- GEDORE vanadium steel 31CrV3, chrome-plated

6.3  
1/4"

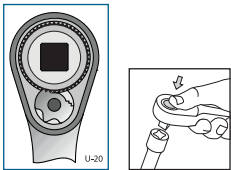

Code	No.	□"	■	∠°	↳mm↳	↳	↔	↳	£
1703749	<b>2093 U-20</b>	1/4	6.3	9	127	20	95	5	

**2093 U-10**

**REVERSIBLE RATCHET 1/4"**

- Acc. to DIN 3122, ISO 3315
- With lever change, locks in middle position
- For hand-operated sockets and accessories with square drive as per DIN 3120 - C 6.3, ISO 1174, ball locking device
- GEDORE vanadium steel 31CrV3, chrome-plated

6.3  
1/4"



Code	No.	□"	■	∠°	↳mm↳	↳	↔	↳	£
6180470	<b>2093 U-10</b>	1/4	6.3	15	129	21.5	109	5	

**2093 U-10 HL**

**REVERSIBLE RATCHET 1/4" HI-LOK®**

- Especially for Hi-Lok® bolts (scrivets) in the aerospace industry
- Lever change ratchet with magnetic locking, from GEDORE vanadium steel 31CrV3
- With lever change, oval head
- For hand-operated sockets
- Hi-Lok® = reg. trademark of Hi-Shear Corporation, Ca. USA

6.3  
1/4"



Code	No.	□"	■	∠°	↳mm↳	↳	↔	↳	£
2226294	<b>2093 U-10 HL</b>	1/4	6.3	15	129	21	105	1	





1/4"

**2093 U-3**

**REVERSIBLE RATCHET 1/4"**

- Acc. to DIN 3122, ISO 3315
- With non-slip metal disc change, fine-toothed and robust
- For hand-operated sockets and accessories with square drive as per DIN 3120 - C 6.3, ISO 1174, ball locking device
- GEDORE vanadium steel 31CrV3, chrome-plated



6.3  
1/4"



Code	No.	□"	■	∠°	↳mm↳	↳	↔	📦	£
6170590	<b>2093 U-3</b>	1/4	6.3	5	129	25	95	5	

 
**2093 Z-94**

**RATCHET HANDLE WITH COUPLER 1/4"**

- Acc. to DIN 3122, ISO 3315
- With square coupler, medium-fine toothed, extremely rugged
- For hand-operated sockets and accessories with square drive as per DIN 3120 - C 6.3, ISO 1174 ball locking device
- GEDORE vanadium steel 31CrV3, chrome-plated



6.3  
1/4"



Code	No.	□"	■	∠°	↳mm↳	↳	↔	📦	£
6170750	<b>2093 Z-94</b>	1/4	6.3	18	129	12	76	5	

**2093 U-3 T**

**RATCHET WITH T-HANDLE 1/4"**

- Two-wing T-handle
- Ergonomic design for comfortable working
- For hand-operated sockets and accessories with square drive as per DIN 3120 - C 6.3, ISO 1174, ball locking device
- The danger of the tool canting, when carrying out work with extensions, is reduced by the central positioning of the square drive



6.3  
1/4"

Code	No.	□"	■	∠°	↳mm↳	↳	↔	📦	£
1791532	<b>2093 U-3 T</b>	1/4	6.3	5	140	65	5		

**2093 HR-94**

**HAND RATCHET 1/4" without handle**

- With square coupler
- Facilitates working quickly in confined spaces where other ratchets or tools do not fit
- Especially suitable for servicing work in conjunction with extension 2090-12
- Dimensions: Ø 26 x 20 mm



6.3  
1/4"



Code	No.	□"	■	∠°	↳mm↳	↳	↔	📦	£
6069870	<b>2093 HR-94</b>	1/4	6.3	18	35	10			