


KEMET Part Number: EFG(02)-240X240 **Not for New Design**
(UFSEFG020AT000, EFG(02)240X240)

KEMET, EFG, Flex Suppressors, Noise Suppression

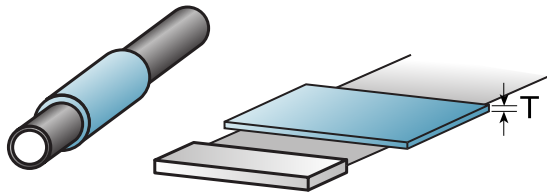

Dimensions

Sheet Size	240x240mm
T	0.2mm +/-0.05mm

Packaging Specifications

Tape Description:	No Adhesive Tape
-------------------	------------------

General Information

Series:	EFG
Style:	Sheet
Description:	Flex Suppressor Halogen Free Type
Features:	High Frequency Specifications
RoHS:	Yes
Qualifications:	UL94 V-1
Environment:	Halogen Free, PVC Free, Lead Free
Notes:	Not recommended for new designs, please see EFG2(02)-240X240 for replacement

Specifications

Temperature Range:	-40/+105°C
Magnetic Permeability:	20 u At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3 Atm TYP
Conductivity:	0.22 W/m K
Tensile Strength:	3.5 MPa